

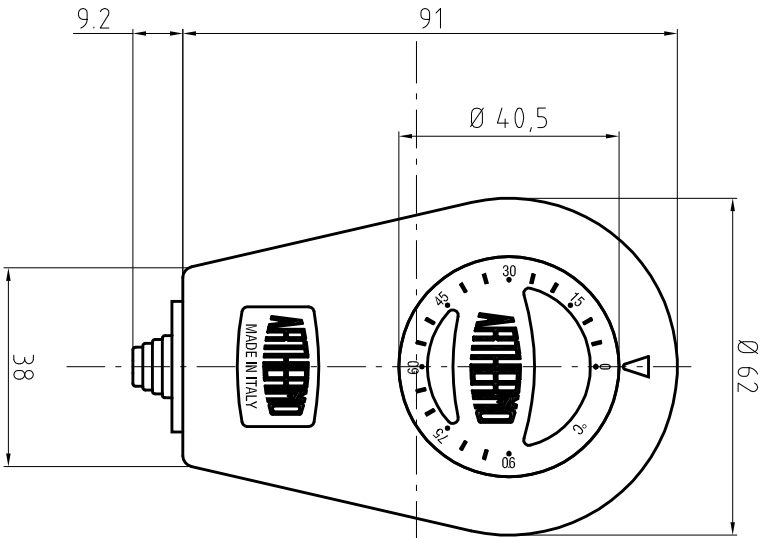
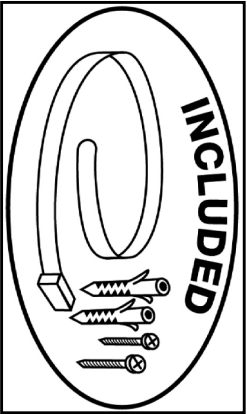


SISTEMA DI FISSAGGIO
FIXING SYSTEM

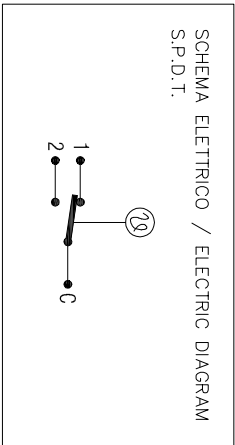

ACCESSORI
ACCESSORIES

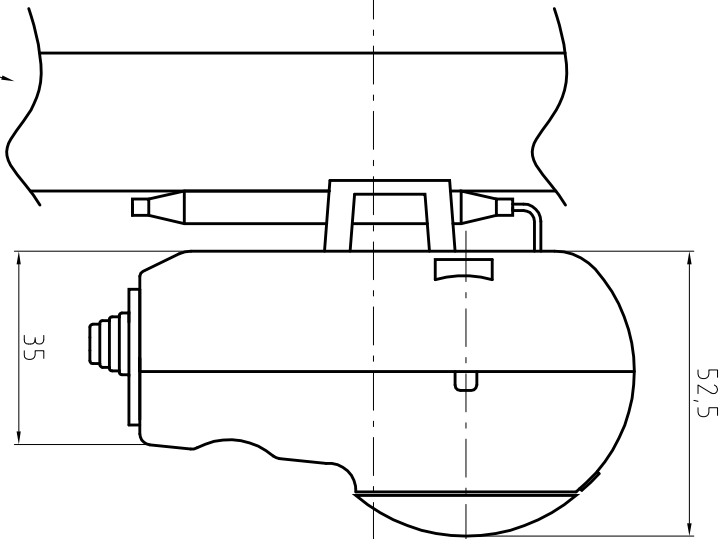

DATI TECNICI - THECNICAL DATA

SCALA RANGE:	0/90°C
DIFFERENZIALE / DIFFERENTIAL:	4 ± 2,5°C
TOLL. VALORI F.S.	± 3°C
CAPILLARE / CAPILLARY:	INOX CAPILLARY
INVOLUCRO MANOPOLA / CASE:	LIGHT BLUE PANTONE 2995C RED KNOB - WHITE NUMBERS
PORTATA CONTATTI / BREAKING CAPACITY:	C1 15(3)A 400 VAC - C2 2,5(0,6)A 400 VAC
MINIMUM CORRENT.:	200 mA
INSULATION RESISTANCE:	>100 M ohm
TEST DI VITA / LIFE OF PRODUCT:	100.000 CICLI / CYCLES
MAX °C SOPR. CORPO / MAX °C CASE	70°C
GRADO TENUTA / IP GRADE:	IP 4.0

MODIFICA		DOC RIF.	DATA	APPARECCHIO ASSIEME	
1				PARTICOLARE	ARTH100
2				MATERIALE	
3				TRATTAMENTO	
4					
5				NOTE	

DISEGNATO A. SALA		APPROVATO SALA A.	
SCALA 1 : 1		DATA 11/11/2011	
CODICE		ARTH300	