

LogiLink®




USB-C 3.2 Gen 1 RGB Lighting Docking Station For 2.5" & 3.5" SATA HDD/SSD

Art. No.: QP0035


Tool-free quick file backup with USB-C connection through 2.5"(6.35 cm)/3.5" (8.89 cm) HDD/SSD.

Features:

- » Compliant with USB 3.2 Gen 1 specification, data transfer up to 5 Gbps
- » Support 2.5" and 3.5" SATA III HDD/SSD, capacity up to 10 TB
- » Compatible with Thunderbolt 3/4
- » Dynamic RGB lighting
- » Silent operation. Safe and stable for data transfer
- » Support USB Hot Plug and Plug & Play
- » 12 V/2 A (24 W) power supply included
- » Compatible with Windows, Mac OS and Linux

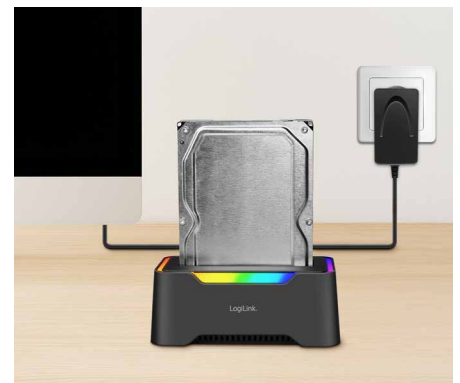

RGB lighting

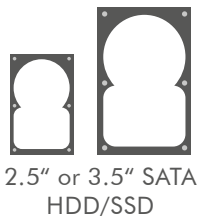

2.5" or 3.5" SATA
HDD/SSD



Excellent heat
dissipation



RGB

ON/OFF

DC 12V


USB-C

USB-C connection to
computer/laptop

External Power Supply



2-in-1 USB-C to
USB-C/USB-A cable

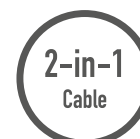


Specification:

USB Version	USB 3.2 Gen 1
Connection	USB-C female
Interface	SATA
SATA Version	SATA I/II/III
Data Transfer Rate	Up to 5 Gbps
Thunderbolt Compatibility	3 & 4
LED Indication	LED for power and activity
SATA Slot Support Type	2.5"/3.5" HDD/SSD
Supporting Hard Drive Capacity	Up to 10 TB
Hot Plug & Plug & Play	Yes
RGB Lighting	Yes
Power & RGB On/Off Switch:	Yes
Power By	DC 12 V/2 A (24 W)
Compatibility	Windows, Mac OS 10.0 or above and Linux
Housing Material	ABS
Color	Black
Operating Temperature	-10–60°C
Operating Humidity	25–60% RH (no condensation)
Dimensions	14.3 x 7.6 x 5.5 cm
Weight	183 g
Cable Length	60 cm

Specification of External Power Supply:

Input Voltage	100–240 V, 50/60 Hz 0.8 A max.
Output Power	12 V/2 A, 24 W
DC Plug	5.5 x 2 x 9.8 mm
Dimensions	79 x 43.8 x 67.9 mm
Cable Length	1.2 m
Weight	105 g

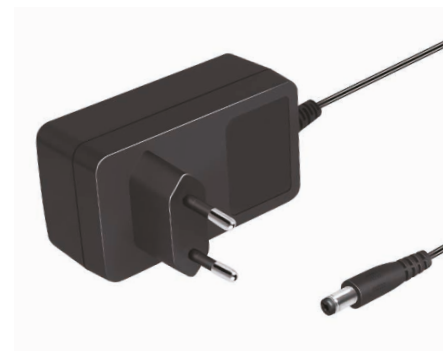

Package Contents:

- » 1x USB-C Docking Station
- » 1x 2-in-1 USB-A/USB-C to USB-C Cable
- » 1x Power Supply
- » 1x User Manual

Package Information:

- » Packing Dimension: 180 x 140 x 70 mm
- » Packing Weight: 0.45 kg
- » Carton Dimension: 380 x 375 x 300 mm
- » Carton Q'ty: 20 pcs
- » Carton Weight: 9.2 kg



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.



QP0035



Made in China