




NFE 25-129
RLS

4.8

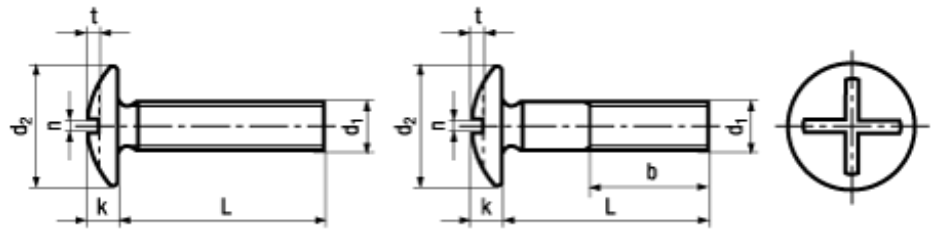

BN 84512

Viti a testa tonda larga

con intaglio, interamente / parzialmente filettate

Acciaio 4.8

zincato bianco

Article#	d ₁	d ₂ max.	k max.	n	t min.	b	L
8094535	M4	10	2,2	1,2	1	-	10
8025274							12
8025282							16
8025290							20
8013810							25
8013829							30
8089140							35
8013837							40
8089159						38	45
8089167							50
8130485							60
8025304	M5	12,5	2,7	1,2	1,2	-	10
8184666							12
8025312							16
8025320							20
8025339							25
8025347							30
8025355							35
8025363							40
8036233							45
8013845							50
8036217						38	60
8130493							70
8130507							80
8130515							90
8130523							100

Article#	d ₁	d ₂ max.	k max.	n	t min.	b	L
8025444	M6	15	3,3	1,6	1,5	-	10
8036225							12
8025452							16
8025460							20
8025533							25
8025541							30
8025568							35
8025576							40
8089175							45
8013853							50
8271356							55
8013861							60
8013888						38	70
8013896							80
8130531							90
8130558							100
8013918	M8	20	4,4	2	2	-	16
8025584							20
8025738							25
8025770							30
8025789							35
8025797							40
8067961							45
8025819							50
8013926							60
8271364						38	65
8013934							70
8013942							80
8130566							90
8013950							100
8013969	M10	25	5,5	2,5	2,4	-	20
8013993							25
8014000							30
8014019							35
8014027							40
8014035							50
8014043							60
8014078						38	70
8014086							80