




**147**

## **5" Swedish Model 90° Pipe Wrench 41.7"**



### PRODUCT DETAILS

- Single-component painted handle
- Slim design of the head allows excellent accessibility in confined spaces compared to many other types of pipe wrenches
- Gripping capacity up to 127 mm (5") and a jaw opening up to 160 mm (6 1/3)
- Patented progressive teeth for better grip
- Anti-rust treated high-alloy steel with induction hardened teeth
- The nut can be blocked in the desired position with the adjustment screw. Safety stop prevents threading-off
- Standards: DIN 5234

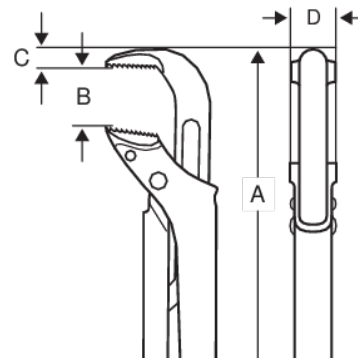

**Follow the Fish!**



PRODUCT ATTRIBUTES

| Product | A       | B      | C     | D     |  |  |
|---------|---------|--------|-------|-------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|
| 147     | 1060 mm | 160 mm | 38 mm | 35 mm | 5 in                                                                                | 7210 g                                                                              |

