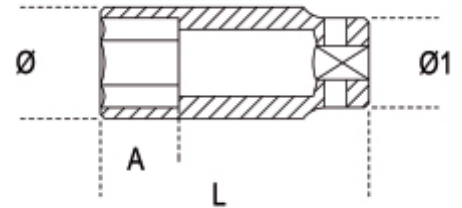

**UNI/ISO 2725**

Art.	Ø mm	Ø mm	L mm	Ø1 mm	A mm	g	
007200310	720L 10	10	17,0	80	25	10,0	152
007200311	720L 11	11	18,5	80	25	11,0	156
007200312	720L 12	12	20,0	80	25	12,0	164
007200313	720L 13	13	21,0	80	25	13,0	159,7
007200314	720L 14	14	22,5	80	25	14,0	175,8
007200315	720L 15	15	23,0	80	30	15	227,6
007200316	720L 16	16	25,0	80	30	16,0	233,8
007200317	720L 17	17	26,0	80	30	17,0	247
007200318	720L 18	18	27,5	80	30	18,0	258
007200319	720L 19	19	28,5	80	30	19,0	242
007200321	720L 21	21	31,0	80	30	21,0	261
007200322	720L 22	22	32,5	80	30	22,0	305,3
007200324	720L 24	24	35,0	80	30	24,0	338
007200327	720L 27	27	38,5	80	30	27,0	398
007200330	720L 30	30	42,0	80	30	29	421
007200332	720L 32	32	44,0	80	30	29	457,4
007200336	720L 36	36	50,0	80	30	31	627,4



**Scan the QR Code to access the web tab**  
 Specs, media and documentation in one click.

