

# USB 5 Gbps USB-C™ + Type-A Memory Stick 16 GB - Metal Housing

## Description

This USB memory stick by Delock can be used to save and transport data, e.g. photos, videos or music. The USB stick can be connected optionally via the **USB Type-C™** or **USB Type-A plug**, the inner part is simply turned and then latch into place. Due to the stylish design with eyelet, the small USB memory stick can be easily attached to the key ring for transport.

### Small sturdy helper

Due to its small dimensions and its sturdy housing, this Delock USB stick is particularly suitable for travelling. Due to its **tiny size**, the USB stick fits into any trouser pocket.



16 GB

**Item no. 54073**

EAN: 4043619540730

Country of origin: China

Package: Retail Box

## Technical details

- Connectors:
  - 1 x USB 5 Gbps Type-A male
  - 1 x USB 5 Gbps USB Type-C™ male
- Capacity: 16 GB
- Maximum read speed: 117 MB/s
- Maximum write speed: 43 MB/s
- Maximum write cycles: 3000
- Operating temperature: 0 °C ~ 70 °C
- Storage temperature: -25 °C ~ 85 °C
- Power consumption: max. 5 W
- Field of application: consumer
- Plug & Play
- Dimensions (LxWxH): ca. 36.8 x 12.1 x 7.1 mm

## System requirements

- Chrome OS 72.0 or above
- Linux Kernel 3.3 or above
- Mac OS 10.14.3 or above
- Windows 7/7-64/8.1/8.1-64/10/10-64/11
- PC or laptop with a free USB Type-A port or

- PC or laptop with a free USB Type-C™ port


---

## Package content

- USB 5 Gbps memory stick

---

## Images

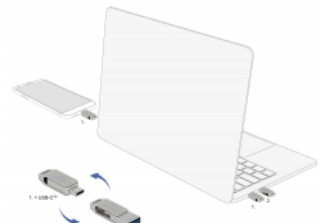

## Interface

Connector:	1 x USB 5 Gbps USB Type-C™ male 1 x USB 5 Gbps Type-A male
------------	---

## Technical characteristics

Storage temperature:	-25 °C ~ 85 °C
Operating temperature:	0° C - 70°C
Read:	117 MB/s
Maximum power consumption:	5 W
Maximum write cycles:	3000
Write:	43 MB/s
Memory capacity:	16 GB

## Physical characteristics

Length:	36.8 mm
Width:	12.1 mm
Height:	7.1 mm

## Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de