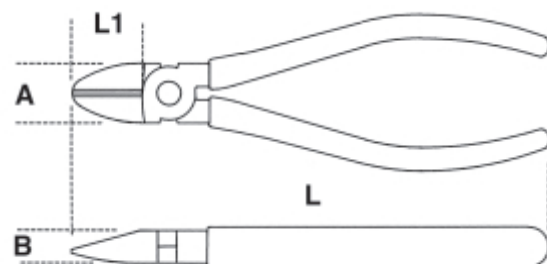


1082MQ
Szczypce tnące boczne, w izolacji do 1000V

EN 60900

	Art.	L mm	L1 mm	 mm	A mm	B mm	L mm	 g
								
010820094	1082MQ 140	140	20	1,6	18	10	150	157
010820096	1082MQ 160	160	22	1,6	20	11	170	221


Zeskanuj kod QR, aby uzyskać dostęp do zakładki

Specyfikacje, media i dokumentacja dostępne za

