

DIGITUS® Universal TV ceiling mount with telescopic height adjustment

DA-90421

EAN 4016032475095



Monitor/TV Ceiling Mount 37"-86", 50 kg max, 560-910 mm, black

The fully flexible universal ceiling mount from DIGITUS® leaves nothing to be desired. It is suitable for flat and curved displays from 37" to 86" screen diagonal and a weight of 50 kg. It can be optimally adapted to different ceiling heights thanks to the telescopic height adjustment. The mount can also be adapted to sloping ceilings with an inclination of up to 60° and can be swiveled 360°. The variable tilt, which can be adjusted from 0 to -25° to the height of the ceiling and the desired viewing angle, ensures the best possible viewing angle. Installation is simplified by the VESA mount with quick-release, as the display and the mounted VESA mount are hooked into the corresponding holders. Cables are neatly routed within the telescopic construction. The integrated spirit level helps with fine adjustment. The ceiling mount can be used for VESA dimensions 200x200 to 600x400.

Variable ceiling mount for flat and curved displays up to 86" / 50 kg, height-adjustable

- Suitable for TVs/monitors from 37" to 86"
- Maximum load: 50 kg max.
- Quick-release function - easy attachment and removal of displays
- VESA mounting dimensions: 200x200, 300x300, 400x200, 400x400, 600x400

- Pivotal: 360° (+180° to -180°)
- Tilttable: -25° to 0° (for optimum viewing angle)
- Rotatable: +3° to -3° (for fine adjustment)
- Variable height adjustment: 56 - 91 cm (center of VESA mount to mounting base)
- Mounting base suitable for pitched roofs: +60° to -60° inclination adjustable
- Cable management: within the tube construction
- Material: Steel
- Dimensions: W 68 x D 43.5 x H 113 cm
- Weight: 5.5 kg
- Color: Black

Attributes




- Monitor weight (max.): 50 kg
- Number of monitors: 1

Package contents

- 1 x Universal TV ceiling mount with telescopic height adjustment
- 1 x mounting accessories
- 1 x QIG

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	3	22.40	38.50	78.00	45.50	136,636.00
Packaging Unit Inside	1	7.47	36.50	76.00	14.50	40,223.00
Packaging Unit Single	1	7.47	36.50	76.00	14.50	40,223.00
Net single without Packaging	1	7.03	36.50	76.00	14.50	40,223.00

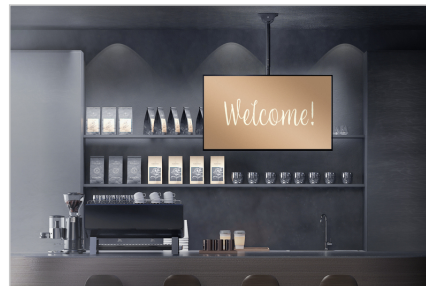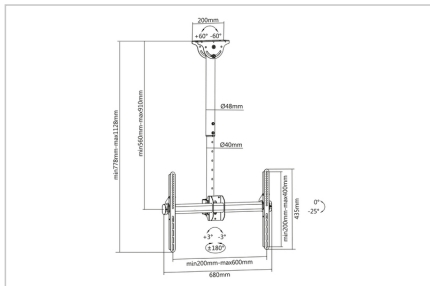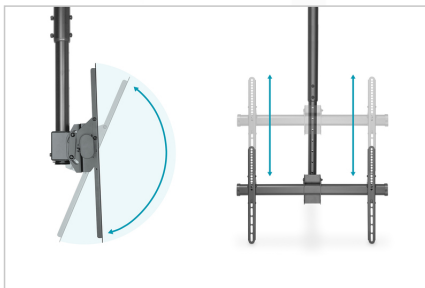

- Please read the entire manual before starting assembly and installation. Please contact your local dealer if you have any questions about the instructions or warnings.
- **CAUTION:** Use with products that exceed the permitted weight may result in damage or possible injury.
- Brackets should be fitted in accordance with the installation instructions. Incorrect installation can result in damage or injury.
- Use safety equipment and suitable tools. The product should only be installed by specialists.
- This product can be installed on timber-framed, solid concrete or stone walls.
- The load-bearing surfaces should be able to safely withstand the entire weight of appliances and all additional components.
- Only use the installation screws supplied and **DO NOT TIGHTEN** the screws **TOO TIGHT**.
- This product contains small parts that can cause a choking hazard if swallowed. Keep these parts away from children.
- Only use this product indoors. Using the product outdoors can lead to injuries and damage.
- **IMPORTANT:** Before installation, please check all components received against the components list. If parts are damaged or missing, ask your local dealer for replacement parts.
- **MAINTENANCE:** Check the bracket regularly for safety and stability (preferably every three months).

ASSMANN Electronic GmbH
Auf dem Schüffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com