



BETA 1924XM

Compact reversible impact wrench



Certifications and Standards



Features

Compact screwdriver made of composite material.

COMPACT AND LIGHTWEIGHT

Pneumatic screwdriver in aluminium alloy, light and compact, easy to transport and handle. Ideal for tight spaces.


HIGH TORQUE

Highest unscrewing torque among tools of the same size and specifications.

FEATURES

- Single hammer impulse device
- Incredibly compact and powerful
- One-handed push-button reversing control

Dimensions

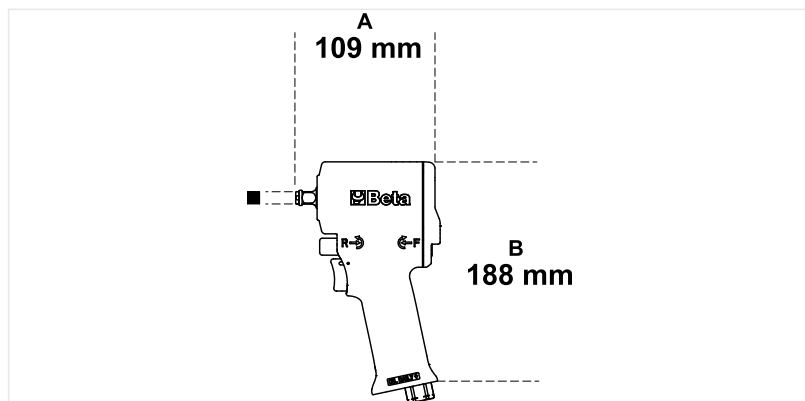

Certifications and Standards



Specifications

FREE SPEED:	9000 rpm
MAX. TORQUE:	515 Nm
BOLT CAPACITY CI 8.8:	M16 □ 24 mm
BOLT CAPACITY CI 12.9:	M14 □ 21 mm
OPERATING PRESSURE:	6.2 bar
MEAN AIR CONSUMPTION:	122 l/min

Coded items

	Art.	L mm	L2 mm	H mm	S mm	S1 mm	R	MI "	kg
019240030	1924XM	113	52	188	57	31,5	1/4" GAS	3/8	1,3

Scan the QR Code to access the web tab

Specs, media and documentation in one click.

