

Illuminated pushbutton Ø 19 mm silver contact

82-5152.1133.B001



<https://eao.com/p/82-5152.1133.B001>

Your product:



82-5152.1133.B001

Illuminated pushbutton Ø 19 mm silver contact

FRONT

Front bezel shape:	flush
Front bezel material:	Stainless steel

MOUNTING

Mounting cut-out:	Ø 19 mm
-------------------	---------

OPERATING-/INDICATION PART

Lens illumination:	illuminative
Lens optics:	opaque
Lens shape:	flush
Illumination colour:	Green
Lens colour:	Silver
Shape of illumination:	Ring
Lens material:	Stainless steel

ELECTRICAL CHARACTERISTICS

Pollution degree:	2, according to EN IEC 60947-1
Rated insulation voltage U_i :	250 V
Rated Operational Voltage U_e :	250 VAC
Switching voltage and switching current:	

according to IEC 60947-5-1 (Silver contacts)	
Service categorie AC-15	
Voltage	Current
24 VAC	1 A
35 VAC	1 A (M12 version)
110 VAC	1 A
220 VAC	0.5 A
Switch rating DC service categorie DC-13 (Silver contacts)	
Voltage	Current
24 VDC	0.7 A
35 VDC	0.5 A (M12 version)
110 VDC	0.2 A
220 VDC	0.1 A

according to UL 508 (Silver contacts)	
cosφ 0,75 ... 0,8	
Voltage	Current
120 VAC	5 A
240 VAC	3 A
24 VAC	1 A

Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground
Electrical lifetime:	50 000 cycles of operation
Thermal current I_{th}:	5 A
Operating voltage:	12 V AC/DC
Contacts:	1 C

MECHANICAL CHARACTERISTIC

Switching system:	Snap-action switching element
Contact material:	Silver
Operating Travel:	ca. 3 mm
Mechanical lifetime:	1 Mio. cycles of operation
Switching action:	Momentary
Operating force:	4 N ... 7 N
Weight:	0.018 kg
Terminal:	Screw terminal
Tightening torque:	0.5 ... 0.6 Nm, Screw terminal 0.1 Nm

AMBIENT CONDITION

Operating temperature:	– 30 °C ... + 70 °C
Shock resistance:	Max. 500 m / s ² as per IEC 60068-2-27
Vibration resistance:	10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6
Climate resistance:	

Damp heat, 21 days according to IEC 60512-11

Storage temperature: - 40 °C ... + 80 °C

CERTIFICATE

Conformities: CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

Approbations: CB, CCC, C UL, UL


OTHER

Short Description: Illuminated pushbutton Ø 19 mm silver contact, Momentary, 12 V AC/DC, 1 C, Screw terminal, Stainless steel, Green, ON/OFF, Silver

Kind of illumination: Single-LED


Symbol: ON/OFF

Dimension drawings:

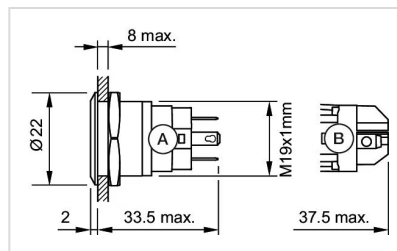


A = Solder terminal
B = Screw terminal

Mounting cut-outs:

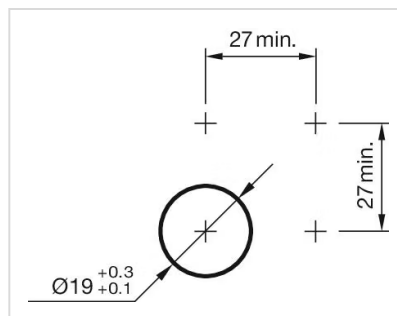

Wiring diagrams:

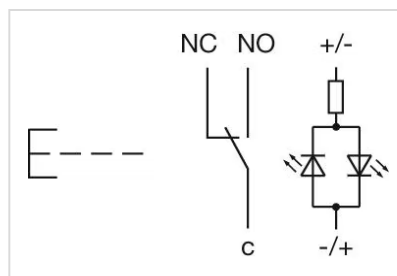

Component layouts:

