


UNI 6737

- Ultrathin wrenches with identical openings
- 15° and 75° head angles, for use in confined spaces.

	Art.	M mm	M1 mm	L mm	H mm	H1 mm	S mm	g
000730040	73 4	4	4	78	13	13	3	10
000730045	73 4,5	4,5	4,5	78	13	13	3	10
000730050	73 5	5	5	78	13	13	3	10
000730055	73 5,5	5,5	5,5	86	16	16	3	13
000730060	73 6	6	6	86	16	16	3	13
000730070	73 7	7	7	86	16	16	3	12
000730080	73 8	8	8	97	20,5	20,5	3,5	22
000730090	73 9	9	9	97	20,5	20,5	3,5	18
000730100	73 10	10	10	108	22,5	22,5	3,5	26
000730110	73 11	11	11	108	22,5	22,5	3,5	26
000730120	73 12	12	12	124	27	27	4	40
000730130	73 13	13	13	124	27	27	4	40
000730140	73 14	14	14	124	27	27	4	40

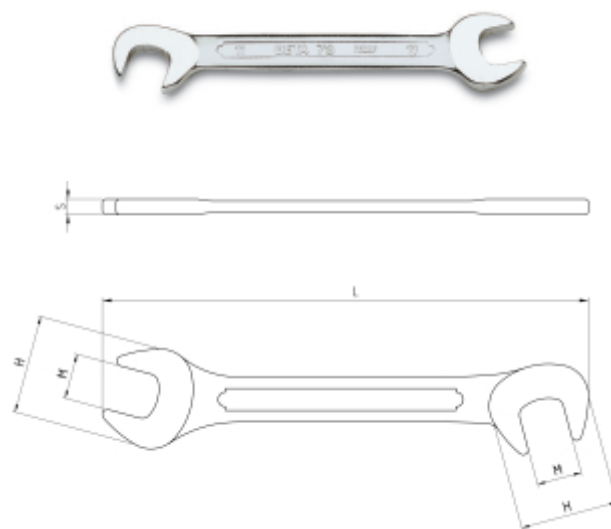

Scan the QR Code to access the web tab

Specs, media and documentation in one click.

