

# USB 2.0 External Hub 4 Port

## Description

This USB hub by Delock can be connected to a computer via the USB Type-A interface. It expands the computer by four USB Type-A connectors. Different USB devices such as docking stations, card reader, external enclosure etc. can be connected.



**Item no. 61393**

EAN: 4043619613939

Country of origin: China

Package: Retail Box

## Technical details

- Connectors:
  - 1 x USB 2.0 Type Mini-B female >
  - 4 x USB 2.0 Type-A female
  - 1 x 5 V DC jack
- Data transfer rate up to 480 Mbps
- Dimensions (LxWxH): ca. 70 x 43 x 20 mm
- Use as self-powered (with power supply) or bus-powered (without power supply)
- Plug & Play

## Power supply specification

- Power supply type: Euro wall power plug
- Model identifier: FJ-SW126K0502000DE
- Input voltage: 100 - 240 V
- Input AC frequency: 50 / 60 Hz
- Input current: 0.4 A
- Output voltage / Output current / Output power: 5.0 V / 2.0 A / 10.0 W
- Average active efficiency: 78.9 %
- No-load power consumption: 0.09 W
- Power supply cable length: ca. 1.2 m
- DC power connector: 3.5 x 1.35 mm
- Ground outside, plus inside

 

## System requirements

- Linux Kernel 2.6 or above
- Mac OS 10.5 or above
- Windows Vista/Vista-64/7/7-64/8.1/8.1-64/10/10-64/11
- PC or laptop with a free USB Type-A port

## Package content

- Hub USB 2.0
- USB 2.0 cable
- External power supply
- User manual

## Images

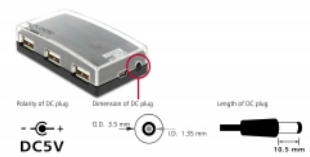

## General

Function:	Plug & Play
Supported operating system:	Linux Kernel 2.6 or above Mac OS 10.5 or above Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows Vista 32-bit Windows Vista 64-bit Windows 11

## Interface

Connector:	1 x USB 2.0 Type Mini-B female 4 x USB 2.0 Type-A female 1 x 5 V DC jack
------------	--

## Technical characteristics

Data transfer rate:	480 Mbps
---------------------	----------

## Physical characteristics

Length:	70 mm
Width:	43 mm
Height:	20 mm

## Power supply

Power supply type:	<b>Power supply specification</b> Euro wall power supply
Model identifier:	<b>Power supply specification</b> FJ-SW126K0502000DE

Input voltage:	<b>Power supply specification</b> 100 - 240 V
Input AC frequency:	<b>Power supply specification</b> 50 / 60 Hz
Input current:	<b>Power supply specification</b> 0.4 A
Output voltage / Output current / Output power:	<b>Power supply specification</b> 5.0 V / 2.0 A / 10.0 W
Average active efficiency:	<b>Power supply specification</b> 78.9 %
No-load power consumption:	<b>Power supply specification</b> 0.09 W
Power supply connector:	<b>Power supply specification</b> DC male 3.5 mm x 1.35 mm Ground outside, plus inside
Cable length of power supply:	<b>Power supply specification</b> 1.2 m

### Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de