


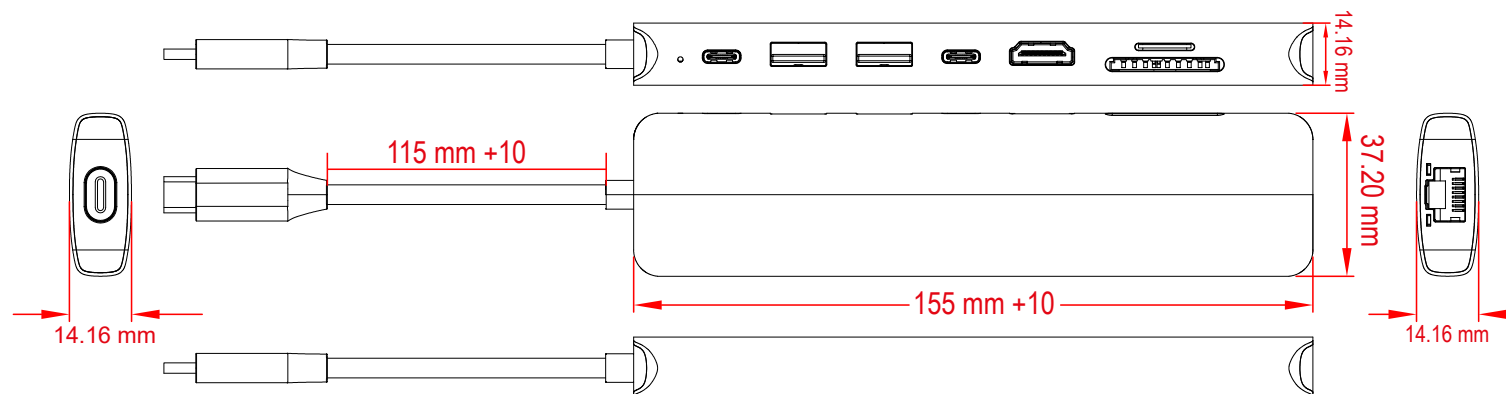

Slim 8-Port USB-Hub mit HDMI™ und RJ45, 5 Gbit/s

- USB-C™-Hub erweitert einen Port auf acht Anschlüsse für vielseitige Peripherie.
- HDMI™-Ausgang unterstützt 4K @ 60 Hz für flüssige, scharfe Bildübertragung.
- USB-A: Daten bis 5 Gbit/s (USB 3.2); USB-C™: 1× Power Delivery 100 W, 1× 480 Mbit/s Daten.
- RJ45-Port (1 Gbit/s) und Cardreader für SD/microSD bis 480 Mbit/s.
- Schlankes, kompaktes Design – ideal für unterwegs.
- Robustes Aluminiumgehäuse für hohe Langlebigkeit.
- Kompatibel mit NVMe-SSDs und Windows, macOS, Linux, Android; abwärtskompatibel zu USB 2.0.

Slim 8-Port USB Hub with HDMI™ and RJ45, 5 Gbit/s

- USB-C™ hub expands a single port into eight connections for versatile peripheral use.
- HDMI™ output supports 4K @ 60 Hz for smooth, sharp image transmission.
- USB-A: data speeds up to 5 Gbps (USB 3.2); USB-C™: 1× Power Delivery 100 W, 1× 480 Mbps data.
- RJ45 port (1 Gbps) and card reader for SD/microSD with speeds up to 480 Mbps.
- Slim, compact design – ideal for travel.
- Durable aluminum housing for enhanced longevity.
- Compatible with NVMe SSDs and Windows, macOS, Linux, Android; backward compatible with USB 2.0.

Änderungen

Datum	Name	gez.:	Datum	Name
19.12.2025	fw	gepr.:	23.10.2025	ir
05.03.2026	fw	Norm:		alw

Änderungen vorbehalten / Subject to change

Bezeichnung

MP HUB USB-C - 8in1
HDMI@60+RJ45+C+A+A+SD+TF+PD

Zeichnungs-Nr.:

79146

goobay®

Blatt

1/2

von

	1	2	3	4	5	6	7	8	9	10	11	12	13	14	
A															A
	Technische Daten							Specifications							
B	Anschlüsse							Connections							B
	Eingang, Typ: USB-C™ 3.2-Stecker							Input, type: USB-C™ 3.2 plug							
	Ausgang, Typ: HDMI™-Buchse (Typ A)							Output, type: HDMI™ socket (type A)							
	Ausgang 2, Typ: RJ45-Buchse (8P2C) (1Gbit/s)							Output 2, type: RJ45 socket (8P2C) (1Gbit/s)							
	Ausgang 3, Typ: USB-C™-PD-Buchse (PD=Power Delivery)							Output 3, type: USB-C™ PD socket							
C	Ausgang 4, Typ: USB-C™ 2.0-Buchse							Output 4, type: USB-C™ 2.0 socket							C
	Ausgang 5, Typ: 2x USB 3.2-Buchse (Typ A)							Output 5, type: 2x USB 3.2 socket (type A)							
	Ausgang 6, Typ: SD-Kartenslot							Output 6, type: SD card slot							
	Ausgang 7, Typ: microSD-Kartenslot							Output 7, type: microSD card slot							
D	Auflösung: 4K/60Hz							Resolution: 4K/60Hz							D
	Kabel							Cable							
	Kabellänge: 0,1 m							Cable length: 0.1 m							
E	Signalübertragung							Signal transmission							E
	max. Übertragungsrate: 5 Gbit/s							max. transmission rate: 5 Gbit/s							
F	Allgemein							General							F
	Farbe: grau							Color: grey							
	Abmessungen (LxBxH): 155 x 37,20 x 14,16 mm							Dimensions (LxWxH): 155 x 37.20 x 14.16 mm							
	Gewicht: 75 g							Weight: 75 g							
G															G
H															H
I															I
J															J