



BETA 1150MQ combination pliers, bright chrome-plated



Certifications and Standards



EN 60900

Features

Insulated combination pliers.

INSULATION 1,000V


EN 60900 certified insulation, guaranteed up to 1000V, for safe working on electrical installations.

OFF-CENTRE PIN

Reduces the physical effort required, improving work efficiency and reducing fatigue, even under prolonged use.

CHROME FINISH

Maximum resistance to corrosion and wear, for a tool that is always flawless and easy to clean, even after intensive use.

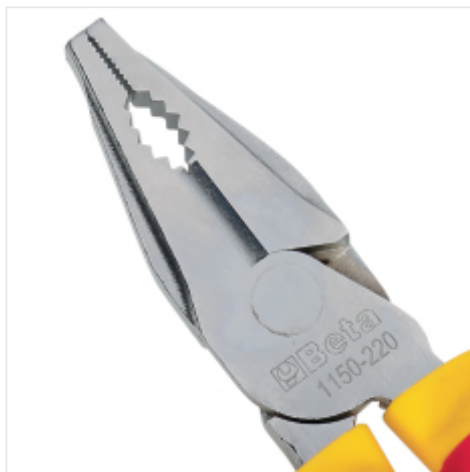

VERSATILITY


Knurled jaws for a secure grip and integrated cutting edges near the fulcrum, ideal for clamping and precisely cutting wires and cables with minimum effort.



HANDLE

Handle ensuring a firm and comfortable grip in every use.

Dimensions

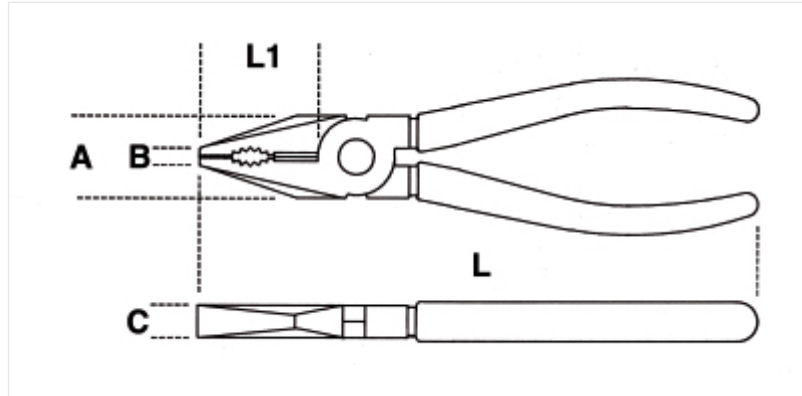

Certifications and Standards

EN 60900

Coded items

	Art.	L mm	L1 mm	 mm	A mm	B mm	C mm	L mm	 g
011500496	1150MQ 160	160	37	1,6	24	6	10	170	197
011500498	1150MQ 180	180	39	1,8	27	7	11	198	283
011500500	1150MQ 200	200	43	2,0	30	8	11	205	322
011500502	1150MQ 220	220	46	2,0	31	8	12	225	405

Scan the QR Code to access the web tab

Specs, media and documentation in one click.

