



 


Obudowa w standardzie niemieckim do montażu ściennego wyposażona w dwubiegunowe listwy zaciskowe i dwa wymienne kołnierze (2 kołnierze z elementami wybijanymi).

Klasa Izolacji	II	Kolor	Szary RAL 7035
Śred. zewn. LxHxD (mm)	298x260x140	Ochrona IP	IP65
Montaż	Montaż ścienny	Odporność na wstrząsy	IK07
Drzwiczki Kolor	Przezroczysty przydymiony	Blok zaciskowy N (mm²)	(3x25)+(10x10)
Blok zaciskowy T (mm²)	(3x25)+(10x10)	Liczba modułów EN 50022	12
Próba rozżarzoną drutem	750 °C	Norma	IEC EN 60670-1; IEC EN 60670-24; DIN VDE 0603-1
Temperatura robocza	-25 +60 °C	Twardość kulkowa	70 °C
Biegun 1 (mm²)	N (3x35) + (10x10)	Biegun 2 (mm²)	E (3x35) + (10x10)

BEHAVIOUR WITH CHEMICAL AND ATMOSPHERIC AGENTS

Saline solution	Acids		Bases		Solvents				Mineral oil	UV rays
	Concentrated	Diluted	Concentrated	Diluted	Hexane	Benzol	Acetone	Ethyl alcohol		
Resistant	Not resistant	Limited resistance	Limited resistance	Not resistant	Limited resistance	Not resistant	Not resistant	Limited resistance	Limited resistance	Resistant

DIMENSIONAL

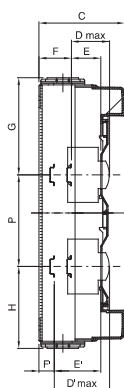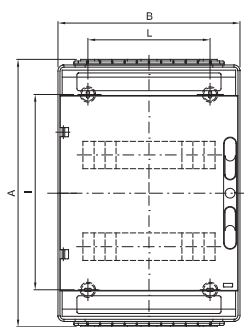

1	2	3	4
M16	M20	M25	M32

	Codice	A	B	C	B	E	F	G	H	P	D'max	E'	F'	NR	I	L
12M	GW 40 113 GW 40 123	278						126.5	151.5	/					161	
24M	GW 40 114 GW 40 124	438	298	140	75	48	48	156.5	131.5	150	102	75	21	4	320	200
36M	GW 40 115 GW 40 125	588						156.5	131.5	150					494	

TECHNICAL SYMBOLOGY



II

IP

IP65


IK

IK07

GWT

750 °C

 INSTALLATION



-25 +60 °C



70 °C

STANDARDS/APPROVALS



GEWISS S.p.A. Via Domenico Bosatelli 1
24069 Cenate Sotto - Bergamo - Italy
tel. +39 035 94 61 11 fax +39 035 94 69 09

www.gewiss.com
sat@gewiss.com
Last update 23/01/2026

Data, measures, designs and pictures are shown only as informative purposes, and could be changed without previous notice