


Capacitor, Film, Metallized Polypropylene, 154 uF, -5/+15% Tol, -25/+55C, ACFilter, 415 VAC

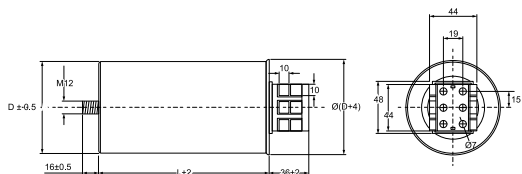

Dimensions (mm)		
Symbol	Dimension	Tolerance
D	85	+/-0.5
L	280	+/-2

Packaging Specifications	
Package Kind:	Bulk
Package Quantity:	9

General Information	
Supplier:	KEMET
Dielectric:	Metallized Polypropylene
Application:	ACFilter
Style:	Aluminum Can
Features:	Three Phase PFC
Mounting Type:	Bolt: M12x16
RoHS:	Yes

Specifications	
Capacitance:	154 uF
Tolerance:	-5/+15%
Voltage AC:	415 VAC
Rated Temperature:	55C
Temperature Range:	-25/+55C
Maximum dVdT:	30 v/us
Current/Ripple Current:	45 Amps
Miscellaneous:	Q = 25 kvar
Miscellaneous:	Operating Freq. = 50 Hz