

TIE10 RecDowel

Rectangular Dowel Clamp 6×5–14×6 mm

RECT PROFILE


DIRECT FIXING

PE MATERIAL

6×5–14×6 MM

2 COLOURS

ROHS COMPLIANT

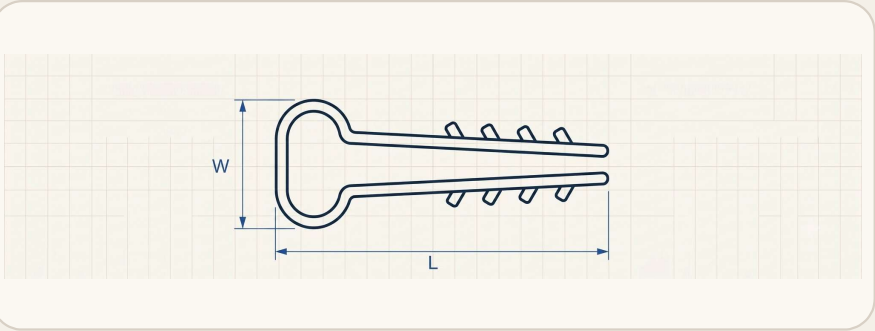

Technical specification

Material	Polyethylene PE
Colours	Black / White
Available sizes	6×5 / 8×5 / 10×5 / 12×6 / 14×6 mm
Working temperature	-15 °C to +80 °C
Installation temperature	-10 °C to +60 °C
Resistant to	Aqueous solutions of salts, acids and alkalis

Range & item codes

ITEM CODE	PRODUCT	COLOUR	PCS/PACK	PCS/CARTON
TTDQ06B	Rectangular Dowel Clamp 6X5 mm	Black	100	7,000
TTDQ06W	Rectangular Dowel Clamp 6X5 mm	White	100	7,000
TTDQ08B	Rectangular Dowel Clamp 8X5 mm	Black	100	6,000
TTDQ08W	Rectangular Dowel Clamp 8X5 mm	White	100	6,000
TTDQ10B	Rectangular Dowel Clamp 10X5 mm	Black	100	6,000
TTDQ10W	Rectangular Dowel Clamp 10X5 mm	White	100	6,000
TTDQ12B	Rectangular Dowel Clamp 12X6 mm	Black	100	6,000
TTDQ12W	Rectangular Dowel Clamp 12X6 mm	White	100	6,000
TTDQ14B	Rectangular Dowel Clamp 14X6 mm	Black	100	5,000
TTDQ14W	Rectangular Dowel Clamp 14X6 mm	White	100	5,000

One datasheet for all RecDowel sizes and colour variants.