



Qoltec Power cable IEC C13 | C14 | 3x1.00mm | Pure copper Cu | 2m

Product code: 54632

The Qoltec IEC C13/14 power cable has been designed to provide stable and safe power supply to electronic devices used both at home and in the office environment. The IEC standard makes the cable fully compatible with a wide range of computer equipment and professional IT installations. The use of bare copper (BC) wires guarantees very good electrical conductivity, low energy losses and reliable operation of connected devices.

RELIABILITY AT HOME, IN THE OFFICE AND IN PROFESSIONAL ENVIRONMENTS



The power cable is designed for use at home and in the office

By choosing the **Qoltec IEC C14/C13 cable**, you get a product that combines reliability with modern design and functionality. It is an excellent choice for anyone looking for proven solutions that will ensure **smooth operation and trouble-free performance of equipment, both in the home office and in demanding professional environments**. Trust the quality that guarantees complete satisfaction!

IEC C13/14 POWER CABLE – RELIABLE POWER SUPPLY FOR IT EQUIPMENT




IEC C14/C13 cable designed for powering computers, monitors, printers and other office equipment
The IEC C14/C13 power cable is the ideal solution for powering a wide range of devices, such as:

- - desktop computers,
- - monitors,
- - printers,
- - switch,
- - UPS emergency power supply,
- - office equipment (fax, scanner).

Ideal for workstations and rack cabinets. Suitable for continuous operation and long-term use.

HIGH QUALITY YOU CAN RELY ON EVERY DAY

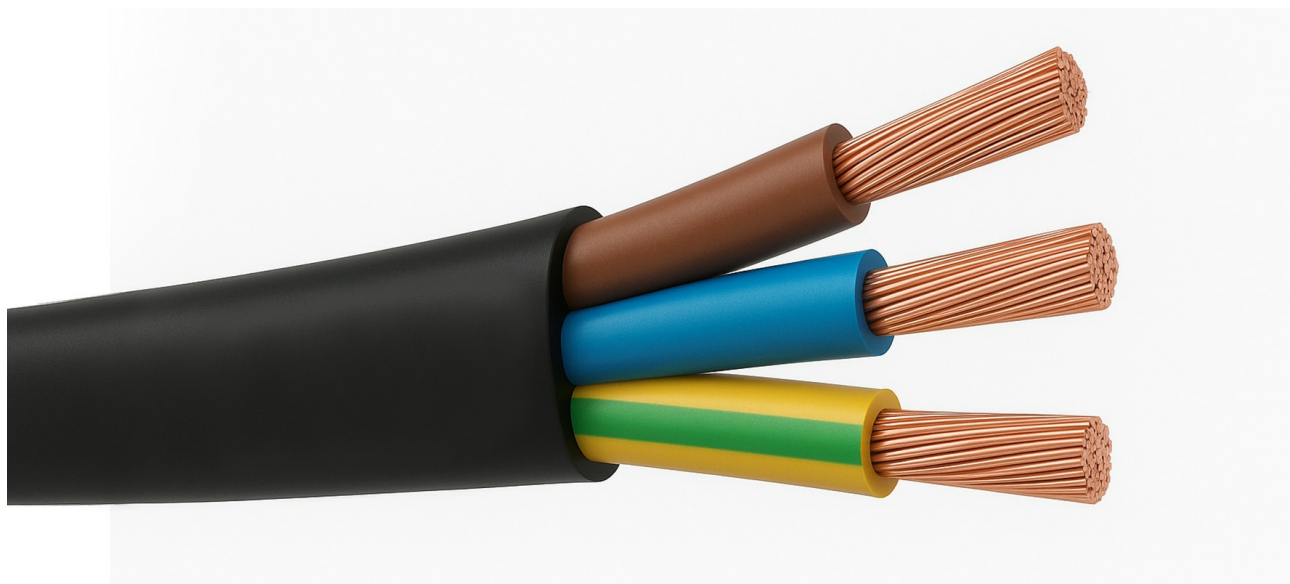

H05VV-F power cable standard, PVC insulation, copper conductors

The exceptional quality of this **H05VV-F** standard cable guarantees durability and safety, even with intensive use. Solid **insulation made of polyvinyl chloride (PVC)** and **three high-quality copper multi-wire conductors** ensure stable power flow without the risk of overheating or failure. The appropriately selected 2 metre cable length provides the freedom to connect devices in hard-to-reach places, eliminating the problem of bulky, tangled cables.

TRUST BACKED BY A GUARANTEE



2-year product warranty

Do you care about the high quality of the product you buy? **Our solutions will meet your expectations.** Each of the power cables we offer is covered by a 24-month warranty valid from the date of purchase.

TECHNICAL DATA

Producer	Qoltec
Type	Power cable
Plug type	IEC C13/C14
Output current	16A 250V~
Standard of cable	H05VV-F
Conductor cross-sectional area	3 * 1.00 mm
Insulating material	PVC
Application	All electrical appliances with the appropriate socket
Usage	- Desktop computers - Monitors - Printers - UPS emergency power supply - Office equipment (fax, scanner)
OTHER PARAMETERS	
Colour	Black
Working temperature	-20 C ~ +60 C
Cable length	2m
Package	Polybag
Package contents	1 x C13/C14 power cable
Package depth / length [mm]	390
Package width [mm]	105
Package height [mm]	25
Net weight [kg]	0.200
Gross weight [kg]	0.203
Warranty	24 month
EAN code	5901878546322