

FILES AND HAMMER

► 5-210

Needle files set 6 pcs

content: article listing see below, precision mechanic files in high-quality
24 strokes on 1 cm, File length 80 mm, Handle length 60 mm
length 140 mm, weight 50 g, 100% Made in Germany

Art.-No.	Type	Handle length	Total length	Weight in g
5-201	flat-blunt	100	140	7
5-202	flat-pointed	100	140	6
5-203	round	100	140	6
5-204	half round	100	140	6
5-205	triangular	100	140	6
5-206	square	100	140	6



► 5-240

Warding files set 6 pcs

content: article listing see below, precision mechanic files in high-quality
22 strokes on 1 cm, File length 103 mm, Handle length 67 mm
length 170 mm, weight 120 g, 100% Made in Germany

Art.-No.	Type	Handle length	Total length	Weight in g
5-231	flat-blunt	67	170	17
5-232	flat-pointed	67	170	14
5-233	round	67	170	13
5-234	half round	67	170	27
5-235	triangular	67	170	18
5-236	square	67	170	15



► 5-261

Contact file


22 strokes on 1 cm, precision mechanic files in high-quality
for cleaning contacts and connections, with fine strokes, flat-blunt
length 150 mm, weight 9 g, 100% Made in Germany



► 7-616

PUK saw 150 mm

Saw blade for wood and metal, span 150 mm
with adjustable wooden handle can be aligned with the frame
length 245 mm, weight 140 g

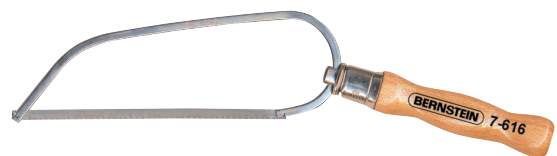

► 7-617 Saw blade for PUK (PU12)

content: 12 pcs, spare part / replacement, metal saw blade
length 150 mm, weight 3 g



► Engineer hammer according to DIN 1041

Drop forged, precision ground, tiller and track precision ground, varnished and
rust-protected, with double curved ash handle

Art.-No.	Total length	Head weight in g	Total weight in g
7-114	280	200	260
7-116	300	300	435

