
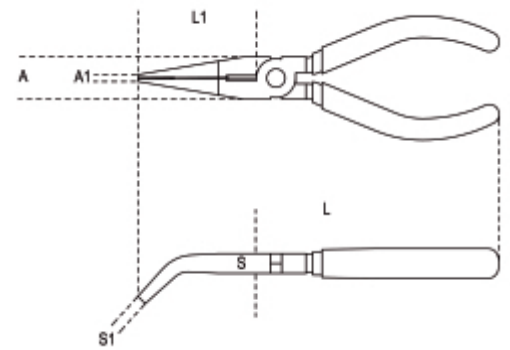



ISO 5745

	Art.	L mm	L1 mm	\varnothing mm	A mm	A1 mm	S mm	S1 mm	\bar{m} g
011680036	1168BM 160	160	54	1,6	19,0	2,5	9,0	3,2	140
011680040	1168BM 200	200	70	1,6	22,0	5,0	11,0	4,0	210



Scan the QR Code to access the web tab
 Specs, media and documentation in one click.

