


	Art.	A mm	L mm	L1 mm	B mm	g
013700528	1370FT 28	28	280	86	22	530
013700530	1370FT 30	30	280	92	24	625
013700532	1370FT 32	32	300	100	26	750
013700536	1370FT 36	36	300	104	29	930
013700540	1370FT 40	40	330	110	33	1150
013700542	1370FT 42	42	330	116	34	1250
013700550	1370FT 50	50	380	138	40	2100
013700560	1370FT 60	60	380	160	42	2750



Zeskanuj kod QR, aby uzyskać dostęp do zakładki

Specyfikacje, media i dokumentacja dostępne za

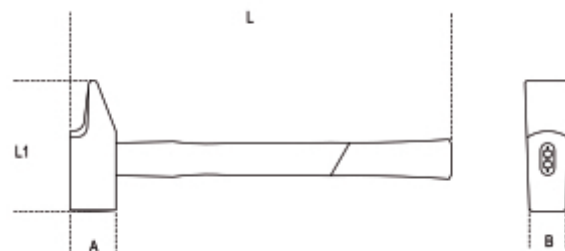