




1256/C36-2
Wkrętak precyzyjny z 36 wymiennymi 4-mm końcówkami wkrętakowymi i magnetycznym przedłużaczem
 200 g



 130x60x35 mm -  200 g

do prac precyzyjnych

W zwartym pudełku z anodowanego aluminium



	art.	
012560100	1256/C36-2	TX ⊕ T3-T4-T5-T6-T7-T8-T9-T10-T15 RTX ⊕ T6-T7-T8-T9-T10 PE ○ 0.7-0.9-1.3-1.5-2.0-2.5 mm LP ● 0.8-1.2-1.5-1.8-2.0-2.5-3.0-3.5-4.0 mm PH ⊕ PH000-PH00-PH0-PH1 PZ ⊕ PZ000-PZ00-PZ0-PZ1

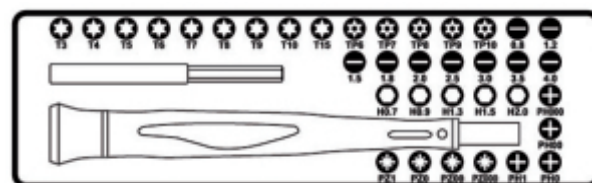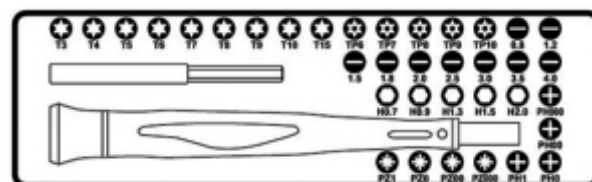

- n. **1256TX:** ⊕ T3 - T4 - T5 - T6 - T7 T8 - T9 - T10 - T15
- n. **1256RTX:** ⊕ T6 - T7 - T8 - T9 - T10
- n. **1256LP:** ● 0,8 - 1,2 - 1,5 - 1,8 - 2 - 2,5 3 - 3,5 - 4 mm
- n. **1256PE:** ○ 0,7 - 0,9 - 1,3 - 1,5 - 2 mm
- n. **1256PH:** ⊕ PH000 - PH00 - PH0 - PH1
- n. **1256PZ:** ⊕ PZ000 - PZ00 - PZ0 - PZ1
- n. **1256/20:**
- n. **1256/30:**