

RS-232 Cable Serial D-Sub 9 female to female null modem with narrow plug housing - Full Handshaking - 5 m

Opis

This serial cable by Delock is a **full handshake null modem cable** with RTS / CTS and DTR / DTS data flow control. This cable offers the possibility to connect RS-232 devices directly with each other. Optionally, devices can be supplied with power via the RI line.

Mini D-Sub 9 connector

These cables fit any RS-232 port, as the **mini D-Sub 9 connectors** (44 x 33.3 x 15 mm) are small and compact. In this way, RS-232 connections can be used next to each other.



5 m

Numer artykułu 87516

EAN: 4043619875160

Kraj pochodzenia: China

Opakowanie: Torba na zamek błyskawiczny

Szczegóły techniczne

- Connectors:
 - 1 x serial D-Sub 9 female with screws >
 - 1 x serial D-Sub 9 female with screws
- Cable gauge: 28 AWG
- Full handshaking cable
- Pin assignment: 2 - 3, 3 - 2, 4 - 6, 6 - 4, 5 - 5, 7 - 8, 8 - 7, 9 - 9, shielded
- Colour: black
- Insulator: PVC
- Screw type: #4-40 UNC
- Cable diameter: ca. 5 mm
- Cable length incl. connectors: ca. 5 m


Wymagania systemowe

- A free D-Sub 9 male port

Zawartość opakowania

- Cable

Zdjęcia

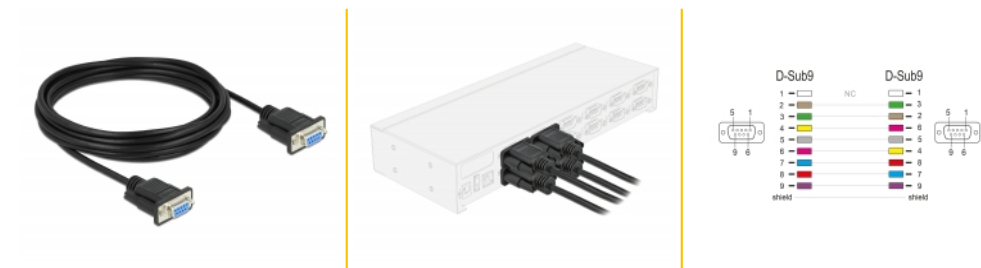

Ogólne

Specyfikacja:	RS-232 (EIA / TIA)
Styl:	Mini Sub-D9 Nullmodem "Full Handshaking" Obie strony identyczne

Interfejs

Złącze 1:	1 x żeński szeregowy D-Sub 9 ze śrubami
Złącze 2:	1 x serial Sub-D 9 female with screws

Właściwości techniczne

Szybkość transmisji danych:	921,6 Kbps
Transmisja sygnału:	TxD, RxD, RTS, CTS, DTR, DSR, RI, GND + Schirmung

Właściwości fizyczne

Typ przewodu:	AWM Style 2464 28 AWG 80 °C 300 V VW-1
Długość kabla ze złączem:	5 m
Wykończenie pinów:	pozlacane
Materiał przewodnika:	Copper tinned
Średnica kabla:	28 AWG 5 mm
Typ śrubek:	#4-40 UNC
Kolor:	czarny
Materiał osłony kabla:	PVC
Bezpieczeństwo palności:	VW-1

Manufacturer information

Ulica	Beeskowdamm 13/15
Kod pocztowy	14167
Miasto	Berlin
Kraj	Deutschland

Email	info@delock.de
Strona internetowa	www.delock.de