



ESD FLOOR RUBBER MATS

E.P.A.

ESD FLOOR RUBBER ROLL MAT

Art. 749DUO ROLL

Colour: GREY with dot decoration

Structure: double layer dissipative/conductive

Thickness 2,5mm

Roll size: 1,9m x 10m (19m²)

Roll weight 3,8 kg/m²

Surface resistance $5 \times 10^6 - 5 \times 10^8$ Ohm

Resistance to ground $5 \times 10^6 - 5 \times 10^8$ Ohm



EXTENDED FLOOR AREA - NO GLUE - SIMPLE AND EFFECTIVE

Save money and time. Use Art.749DUO ESD rubber mat for your EPA also for larger flooring applications.


In fact the bottom black conductive layer ensures a perfect grounding - no glue needed.

Use art REA-MAT self-adhesive copper band for effective grounding.


No glueing needed, no specialized workmanship.

You can re-cycle the mat in a new area just rolling it up again.


Remember to maintain the 749DUO surface clean, for the best ground contact with operators shoes and trolley wheels.

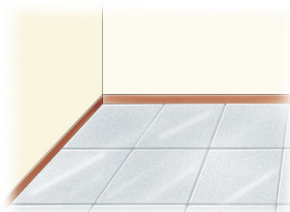


1-clean subfloor

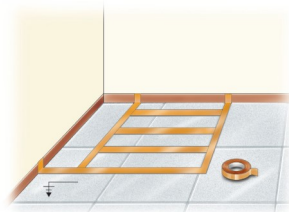


2-lay down copper band

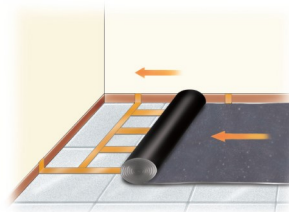

3-lay down rubber mat roll

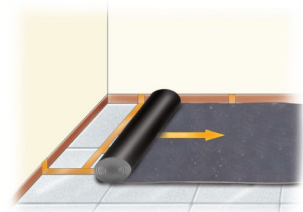

4-remove easily (not glued)

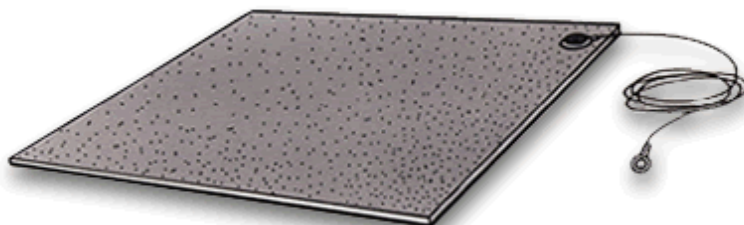

Art. 749DUO KIT

ESD floor mat kit 1200x1900mm includes one 749DUO floor mat cut with a 10mm ground stud and one Art.601 ground cord

Art. 749DUO RUNNER KIT

Flooring runner kit for passage areas (personnel and trolleys). Includes one cut art 749DUO size 950x3000mm, ground cord art 601 and 2 ground male snaps (ground connection points)

