


mm [inch]

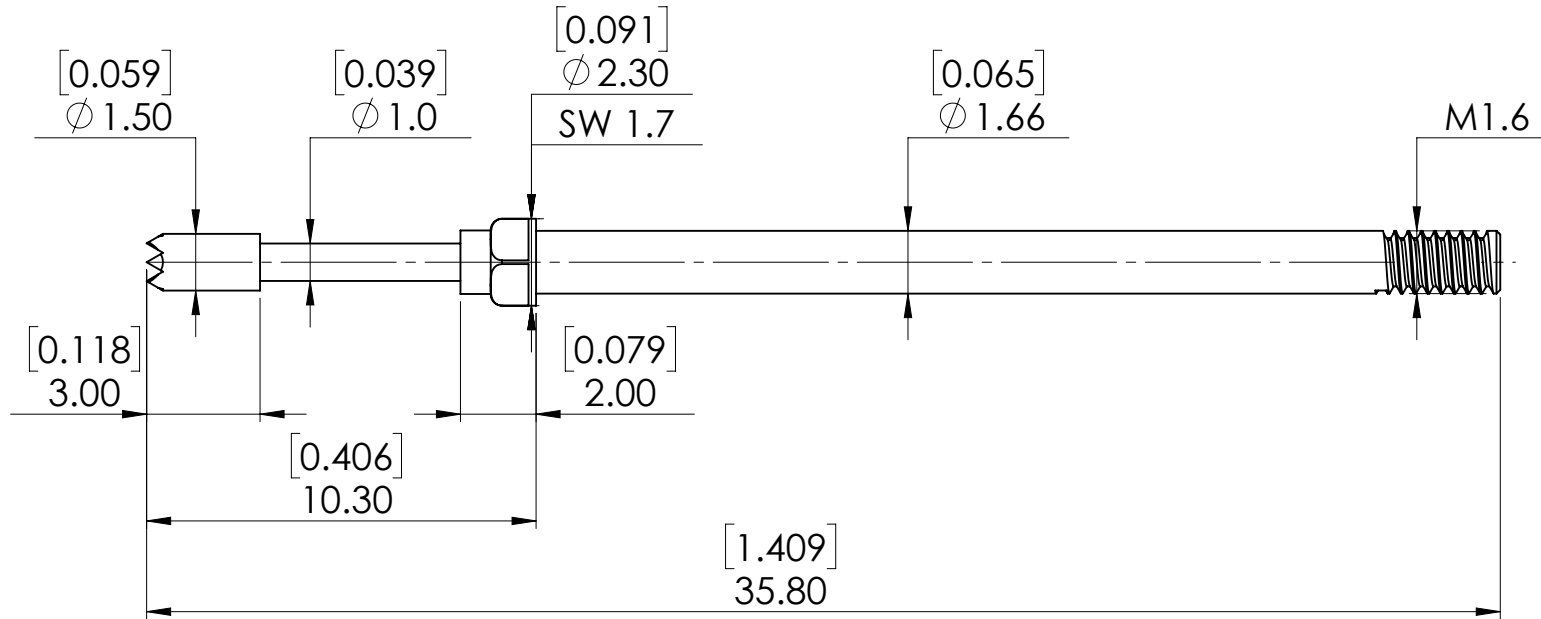

TT1005 CG05 MX

Minimum centers: 2.54 [.100]
 Full travel: 5.30 [.208]
 Working travel: 4.00 [.173]
 Current rating: 5-8 A
 Probe resistance: < 20m Ω
 Operating temperature: -40°C up to +150°C
 Plunger material: BeCu / gold plated
 Barrel material: Brass / gold plated
 Spring material: Music Wire / gold plated
 Maximum tightening torque: 5 Ncm

Spring force at working stroke: 1.5 N [5.4 oz]



© COPYRIGHT 2020 EQUIP-TEST KFT. ALL RIGHTS RESERVED This drawing, model, intellectual product belongs to Equip-Test Kft. Forwarding it to 3rd. party, copying it or using for any other purpose without the written approval of Equip-Test Kft., could entail to legal and criminal procedure!	Name		Date	Catalog Item:	
	Designed	Cs.V.	08.08.2021.	TT1005 CG05 MX	
	Drawn			Drawing No.:	
	Checked				
Note					
			A4	SHEET 1 OF 1	
			TEST - SUPPORT - INNOVATE		