 



mm [inch]

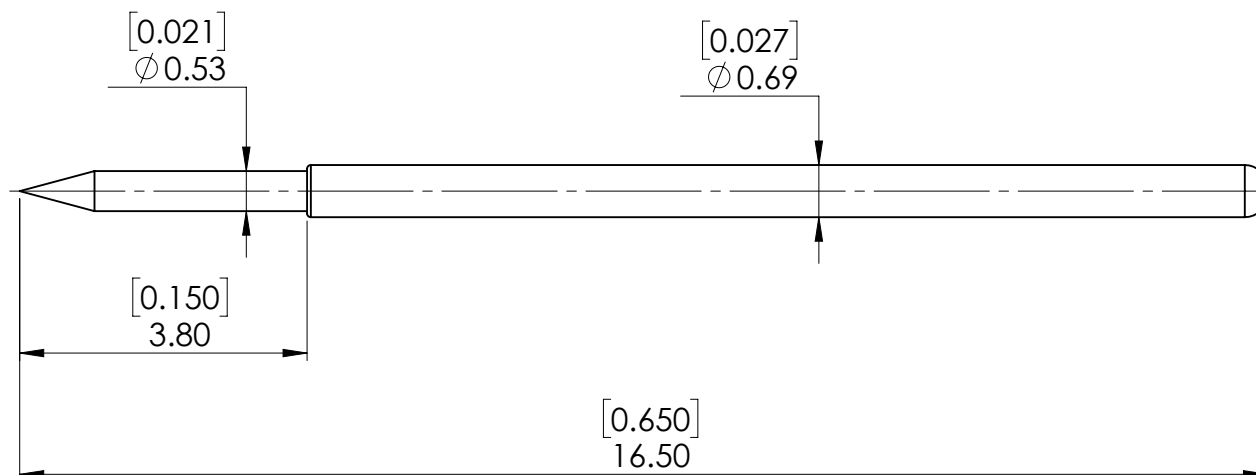

ST510 UB03 MX

Minimum centers: 1.27 [.050]
 Full travel: 2.80 [.110]
 Working travel: 2.20 [.087]
 Current rating: 3 A
 Probe resistance: < 20 mΩ
 Operating temperature: -30°C up to +120°C
 Plunger material: BeCu / gold plated
 Barrel material: PhBr / gold plated
 Spring material: Spring steel / gold plated

Spring force at working stroke: 0.70 N [2.5 oz]

© COPYRIGHT 2018 EQUIP-TEST KFT. ALL RIGHTS RESERVED This drawing, model, intellectual product belongs to Equip-Test Kft. Forwarding it to 3rd. party, copying it or using for any other purpose without the written approval of Equip-Test Kft., could entail to legal and criminal procedure!		Name	Date	Catalog Item:	
	Designed	Cs.V.	06.02.2020.	ST510 UB03 MX	
	Drawed			Drawing No.:	
	Checked				
Note					
			A4	SHEET 1 OF 1	