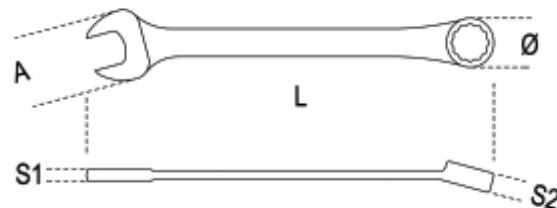


142SN
swivel end ratcheting combination wrenches
ISO 21982:2020

- Head bent at 15°
- Take-up angle: 5°
- Head swivels 180°

	Art.	M mm	M1 mm	L mm	Ø mm	S mm	S1 mm	A mm	g
001420207	142SN 7	7	7	136	18,2	7,4	5,1	18	41
001420208	142SN 8	8	8	136	17,5	7	4,5	17,1	39
001420209	142SN 9	9	9	143	19,3	7,6	4,8	19,2	44
001420210	142SN 10	10	10	160	21	7,7	5,2	21,3	61
001420211	142SN 11	11	11	168	22,7	8,3	5,5	23,7	76
001420212	142SN 12	12	12	174	24	8,7	5,8	25,8	91
001420213	142SN 13	13	13	180	26	9,3	6,1	26,8	105
001420214	142SN 14	14	14	193	27,7	9,4	6,8	30,4	127
001420215	142SN 15	15	15	200	29,1	10	7,2	32,1	146
001420216	142SN 16	16	16	216	30,7	10,6	7,6	33,8	181
001420217	142SN 17	17	17	233	32,6	10,6	8,3	37	210
001420218	142SN 18	18	18	239	33,7	11,2	8,6	38,7	228
001420219	142SN 19	19	19	250	34,8	11,5	9,0	40,2	266
001420222	142SN 22	22	22	285	42,4	13	10,7	46,5	395
001420224	142SN 24	24	24	325	47,9	14,5	11,5	52,3	550


Scan the QR Code to access the web tab

Specs, media and documentation in one click.

