


# FTP Cat5e Patch cord, grey, 1.5 m

PP22-1.5M

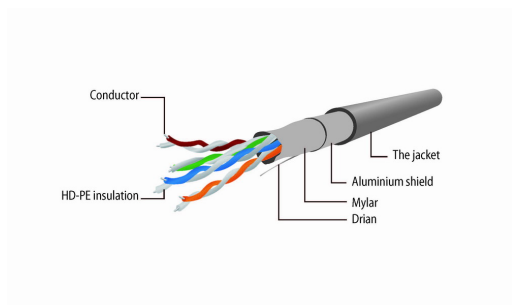

## Cechy produktu

- Foil shielded twisted pair patch cord

## Specyfikacja

Category: Enhanced category 5  
Type: FTP ( foil shielded)  
Frequency bandwidth: Max. 100 MHz  
Compliance with ANSI / TIA / EIA-568B standards  
Conductor: AWG 26 (7 x 0.15 mm wire), CCA  
Conductor insulation: HDPE 0.85 mm  
Shielding: AL foil  
LDPE filler: n/a  
Polyester tape: yes  
Drain wire: yes (7 x 0.12 mm CCA)  
Jacket material: PVC  
Jacket braiding: n/a  
Jacket outer diameter: 5.0 mm  
Length: conform item description  
Color: conform item description

## Opakowanie

|                        |                |
|------------------------|----------------|
| Ilość sztuk w kartonie | 200            |
| Objętość kartonu       | 0.043          |
| Waga kartonu, kg       | 9.8            |
| Wymiary opakowania:    | 170x115x30 mm  |
| Wymiary kartonu DxDxW  | 400x400x270 mm |
| Kraj pochodzenia       | CN             |
| Kod kreskowy EAN       | 8716309044714  |
| Kod celny              | 8544421000     |

## Certyfikaty

