
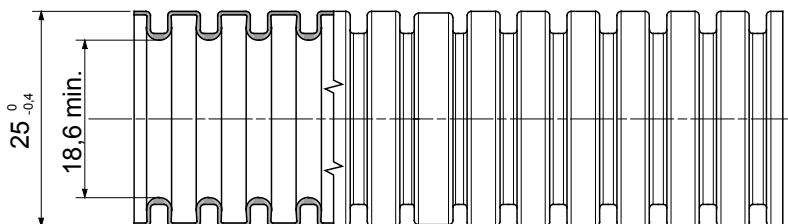


Light pliable conduits FK9 range, made of PVC, classification 22212, available in six diameters, from 16 to 50 mm, with or without cable puller, colour grey RAL 7035. Suitable for electrical and/or data transmission systems. Recommended for concealed installation in vertical walls or ceilings. The FK9 conduits comply with the standards EN 61386-1 and EN 61386-22.

|                                     |                                                |                                                                 |                                           |
|-------------------------------------|------------------------------------------------|-----------------------------------------------------------------|-------------------------------------------|
| Colour                              | Grey RAL 7035                                  | Material                                                        | PVC                                       |
| Type                                | without cable puller                           | Conduits Ø (mm)                                                 | 25                                        |
| Glow Wire Test                      | 960 °C                                         | Resistance to compression                                       | 2 (Light - 320 N)                         |
| Resistance to impact                | 2 (Light - 320 N)                              | Resistance to bending                                           | 2 (Pliable)                               |
| Electrical characteristics          | 2 (With electrical insulating characteristics) | Protection against ingress of solid objects without accessories | 0                                         |
| Protection against ingress of water | 0                                              | Resistance against corrosion                                    | Not applicable to plastic conduit systems |
| Fire resistance                     | 1 (Non-flame propagating)                      | Protection against ingress of solid objects with GF coupling    | 4                                         |
| Standard                            | EN 61386-1 EN 61386-22                         | Classification                                                  | 22212                                     |

### DIMENSIONAL

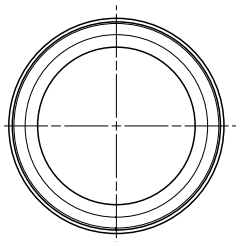

### TECHNICAL SYMBOLOGY



960 °C

### STANDARDS/APPROVALS

