

USB 10 Gbps Docking Station for 2.5" / 3.5" SATA HDD / SSD or M.2 NVMe PCIe or SATA SSD with fan

Description

This docking station by Delock enables an external connection of one **2.5" or 3.5" SATA HDD or SSD** or one **M.2 NVMe or SATA SSD** through the **USB interface**. This solution does not require an external enclosure since the drive can be plugged into the docking station directly.

Good cooling

A **large fan**, which is located directly behind the inserted memory, ensures sufficient cooling of the SSD or HDD. The fan can be switched on or off separately.

Extensive connectivity

Due to the specially designed adapter, the Delock docking station can be quickly and easily connected to the USB Type-A socket. Thus, it can be easily connected to new devices with USB Type-C™ female and older devices that only have a USB Type-A connector. The **adapter is located directly on the cable** and therefore it cannot be lost.



Item no. 64280

EAN: 4043619642809

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x USB 10 Gbps USB Type-C™ female
 - 1 x SATA 6 Gb/s 22 pin receptacle
 - 1 x M.2 key M slot
 - 1 x DC jack
- Adapter:
 - 1 x USB 10 Gbps USB Type-C™ female
 - 1 x USB 10 Gbps Type-A male
- Chipset: Realtek RTL9210B
- Function key:
 - 1 x On / Off switch
 - 1 x on / off switch for the fan
- For 2.5" and 3.5" SATA HDD / SSD
- Suitable for all SATA HDDs up to SATA 6 Gb/s
- Supports M.2 modules with key M or key B+M based on SATA or PCIe (NVMe)
- It can only be used one memory, not both at the same time
- Bootable
- Data transfer rate up to 10 Gbps

- LED indicator for power and access
- 1 x 80 x 80 mm fan
- Dimensions (LxWxH): ca. 166 x 110 x 108 mm
- Plug & Play

Power supply specification

- Wall power supply
- Input: AC 100 ~ 240 V / 50 ~ 60 Hz / 0.6 A
- Output: 12.0 V / 2.0 A / 24.0 W
- Ground outside, plus inside
- Dimensions:
 - inside: $\varnothing$ ca. 2.1 mm
 - outside: $\varnothing$ ca. 5.5 mm
 - length: ca. 10 mm


System requirements

- Android 13.0 or above
- Chrome OS
- Linux Kernel 6.2 or above
- Mac OS 12.4 or above
- Windows 10/10-64/11
- iPad Air (4th Generation) or above
- iPad Pro (3rd Generation) or above
- Surface Pro 7
- Device with a free USB Type-C™ port or with a free Thunderbolt™ 3 or Thunderbolt™ 4 port or
- A free USB Type-A port

Package content

- Docking station
- Cable USB-C™ male to USB-C™ male (with adapter to USB Type-A male), length ca. 80 cm
- External power supply 12.0 V / 2.0 A
- User manual

Images

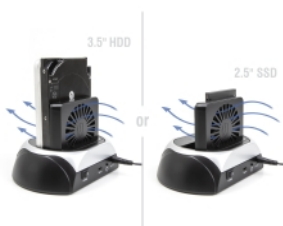

General

Function:	Plug & Play bootable
Suitable for data medium:	2.5" 3.5" SSD or HDD
Supported operating system:	Chrome OS Surface Pro 7 Windows 10 32-Bit Windows 10 64-Bit iPad Pro (3rd Generation) or above iPad Air (4th Generation) or above Windows 11 Mac OS 12.4 oder höher Linux Kernel 6.2 or above Android 13.0 or above

Interface

External:	1 x DC jack 1 x USB 10 Gbps USB Type-C™ female
Internal:	1 x SATA 6 Gb/s 22 pin receptacle 1 x M.2 key M slot

Technical characteristics

Chipset:	Realtek RTL9210B
Data transfer rate:	10 Gbps

Physical characteristics

Housing material:	Plastic
Length:	166 mm
Width:	110 mm
Height:	108 mm



Colour:

grey

black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de