

USB Sound Adapter 7.1

Description

The Delock USB sound adapter expands your computer by one additional sound card. Just plug the adapter to a free USB port of your laptop or PC and connect your headset or speaker to it.

Please Note

The product is not suitable for microphones with a 4 pin jack connection.



Item no. 61645

EAN: 4043619616459

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x USB 2.0 Type-A male >
 - 1 x microphone 3.5 mm 3 pin mono jack female
 - 1 x speaker 3.5 mm 3 pin stereo jack female
- Chipset: CMedia CM119
- Functional keys: Volume-UP, Volume-Down, Mute
- USB audio device specification 1.0
- USB HID class 1.1
- Sample rate: 16 Bit / 48 kHz
- Signal-to-noise ratio (SNR): ca. 90 dB
- Supports virtual 7.1 channel Sound, Xear 3D
- USB bus powered


System requirements

- Linux Kernel 3.7 or above
- Mac OS 10.8 or above
- Windows Vista/7/8.1/10/11
- PC or laptop with a free USB Type-A port

Package content

- USB sound adapter
- CD Software Xear 3D (for Windows Vista/7/8.1/10/11)
- User manual

Images

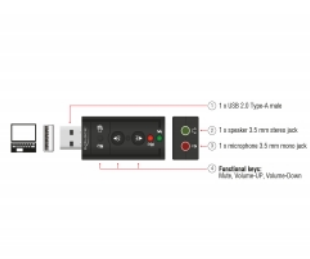

General

Function:	Plug & Play
Specification:	USB 2.0 USB Audio Device Class 1.0 USB HID class 1.1
Supported operating system:	Chrome OS Linux Kernel 3.7 or above Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows Vista 32-bit Windows Vista 64-bit Windows 11 Mac OS 10.8 or above

Interface

Connector 1:	1 x USB 2.0 Type-A male
Connector 2:	1 x microphone 3.5 mm 3 pin mono jack female
Connector 3:	1 x speaker 3.5 mm 3 pin stereo jack female

Technical characteristics

Chipset:	CMedia CM119
Sample rate:	16 Bit / 48 kHz
Signal noise ratio (SNR):	ca. 90 dB
Support:	Virtual 7.1 channel Sound, Xear 3D

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de

Website www.delock.de