


E37511



Thermowell for temperature sensors

THERMOWELL, D6/ G1/2 conical/L=100

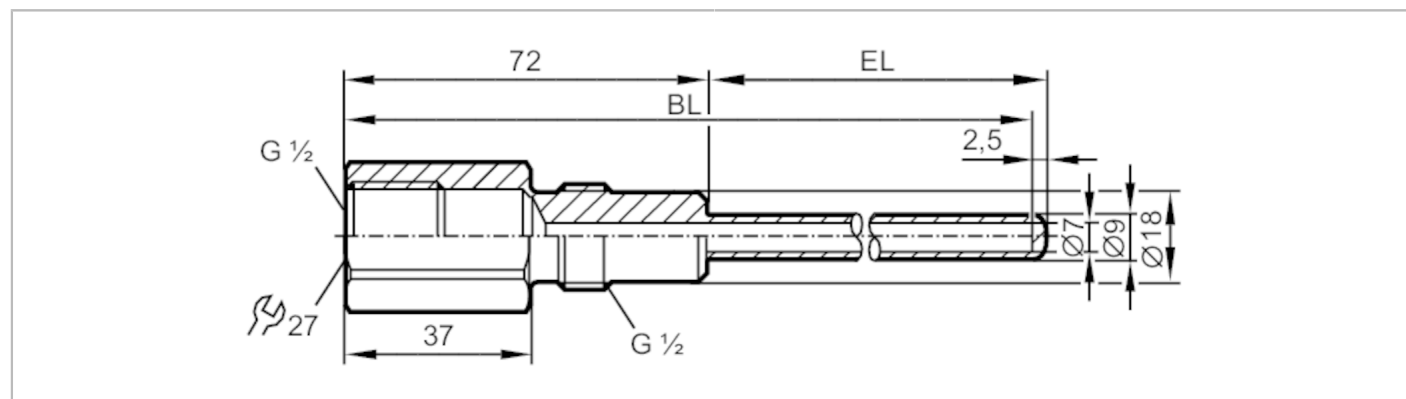

EC 1935/2004 EHEDG Tested

Application		
Design		for temperature sensors EL = 100 mm
Pressure rating	[bar]	16
Pressure rating	[MPa]	1.6
Mechanical data		
Weight	[g]	184.3
Materials		stainless steel (316L/1.4404)
Sensor connection		G 1/2 sealing cone Ø 6 mm
Process connection		G 1/2
Surface characteristics Ra/Rz of the wetted parts		≤ 0.6 / -
Installation length EL	[mm]	68
Bore length BL	[mm]	137
Remarks		
Pack quantity		1 pcs.