








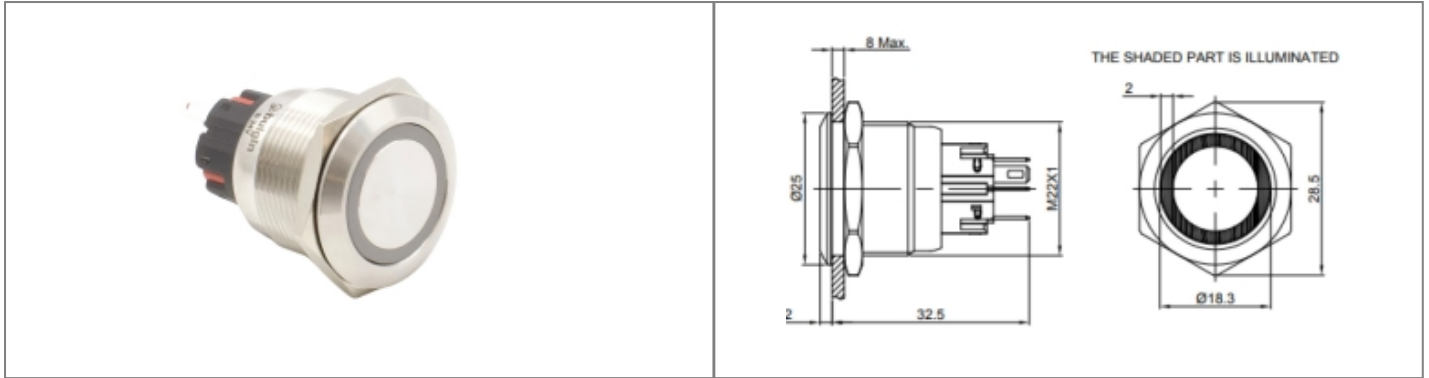

**Product Name // MP22DMRINRR006S5 Ring Illumination  
Vandal Resistant Switch**
 [View Product Page](#)

**// Product Description:**

- |   |   |
|---|---|
|  MP22 Range          |  Red               |
|  DPDT               |  6V               |
|  Momentary         |  Stainless Steel |
|  Ring Illumination |  IP65            |

**// General Information:**

Product Display Title:	Ring Illumination Vandal Resistant Switch
Product Family:	Switch Range
Product Series:	Vandal Resistant Switches
Bezel Finish:	Machined
Body Colour:	Stainless Steel
Body Material:	Stainless Steel
Body Material Type:	Metal
Current Rating:	5A 250V
Diameter:	22mm
Dielectric Withstanding Voltage:	1500V
Durability:	50,000
Function:	Push Button Switch
Illumination Colour:	Red
Illumination Shape:	Ring
Illumination Voltage:	6V
Ip Rating:	IP65
Lamp Type:	LED
Material Finish:	Machined
Max Operating Temperature:	55°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	8mm
Operating Humidity:	45~85 RH(Non condensing)
Panel Cut Out:	22mm Diameter circle
Rohs Compliant:	Yes
Switch Body Colour:	Stainless Steel
Switch Body Material:	Stainless Steel
Switch Button Colour:	Stainless Steel
Switch Button Material:	Stainless Steel
Switch Circuit:	DPDT
Switch Series:	MP22
Switch Shape:	Round
Switch Type:	Pushbutton
Switching Type:	Momentary
Thread Size:	M22

**// Product PDF Links**
 [22mm Vandal Resistant Switch](#)
**// Product 3D CAD Model Links**
 [MP22DMRINRR006S53D CAD Model](#)

 Have a question or project enquiry  
you'd like to talk to us about?

[Click Here To Contact Us](#)