

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0638130800**
Status: **Active**
Overview: Application Tooling
Description: Manual Extraction Tool


Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Application Tooling
Series	<u>207121</u>
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	<u>Application Tooling</u>
Product Name	N/A
Tool Type	Extraction Hand Tool
UPC	800754250429
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers
Application Tooling Documents

ATS-638130800, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

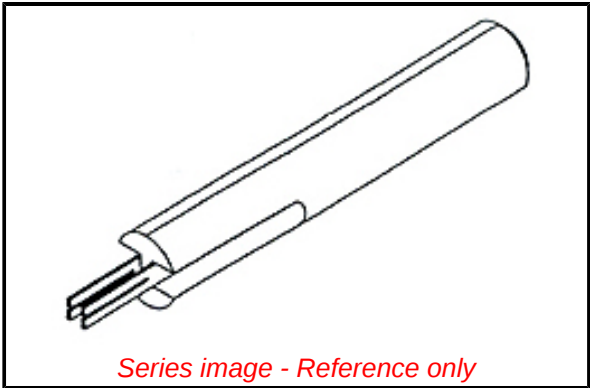

EU ELV Not Relevant	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Relevant	China RoHS
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
207121 Series

Application Tooling Description	FAQ Product #
Sabre Crimp Terminal, Male, 18 AWG, 3.30mm Max. Insulation Diameter, Reel Packaged, Unplated, Brass Contact	<u>431781001</u>
Sabre Crimp Terminal, Male, 18 AWG, 3.30mm Max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact	<u>431781002</u>
Sabre Crimp Terminal, Male, Double 20 AWG, 4.57mm Max. Insulation Diameter, Reel Packaged, Unplated, Brass Contact	<u>431782001</u>

	Sabre Crimp Terminal, Male, 14-16 AWG or double 18-20 AWG, 4.57mm Max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact	<u>431782002</u>
	Sabre Crimp Terminal, Male, Double 18 AWG, 4.57mm Max. Insulation Diameter, Reel Packaged, Unplated, Brass Contact	<u>431783001</u>
	Sabre Crimp Terminal, Male, 18-20 AWG, 3.30mm max. Insulation Diameter, Reel Packaged, Unplated, Brass Contact	<u>431784001</u>
	Sabre Crimp Terminal, Male, 18-20 AWG, 3.30mm max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact	<u>431784002</u>
	Sabre Crimp Terminal, Male, 18 AWG, 3.30mm Max. Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact, Last- Make Wipe Length, complies with the UL1977 finger proof access requirement	<u>431785002</u>
	Sabre Crimp Terminal, Male, 14-18 AWG, 4.57mm Insulation Diameter, Reel Packaged, Tin (Sn) Plated Brass Contact, Last- Make Wipe Length, complies with the UL1977 finger proof access requirement	<u>431786002</u>
	7.50mm Pitch Sabre Plug Crimp Housing, UL 94V-2, 2 Circuits, Natural	<u>436801002</u>
	7.50mm Pitch Sabre Plug Crimp Housing, UL 94V-2, 3 Circuits, Natural	<u>436801003</u>
	7.50mm Pitch Sabre Plug Crimp Housing, UL 94V-2, 4 Circuits, Natural	<u>436801004</u>

7.50mm Pitch Sabre [436801005](#)
Plug Crimp Housing,
UL 94V-2, 5 Circuits,
Natural

7.50mm Pitch Sabre [436801006](#)
Plug Crimp Housing,
UL 94V-2, 6 Circuits,
Natural

7.50mm Pitch Sabre [436802002](#)
Plug Crimp Housing,
UL 94V-0, 2 Circuits,
Black, Black

7.50mm Pitch Sabre [436802003](#)
Plug Crimp Housing,
UL 94V-0, 3 Circuits,
Black, Black

7.50mm Pitch Sabre [436802004](#)
Plug Crimp Housing,
UL 94V-0, 4 Circuits,
Black, Black

7.50mm Pitch Sabre [436802005](#)
Plug Crimp Housing,
UL 94V-0, 5 Circuits,
Black, Black

7.50mm Pitch Sabre [436802006](#)
Plug Crimp Housing,
UL 94V-0, 6 Circuits,
Black, Black

7.50mm Pitch Sabre [436803002](#)
Plug Housing, UL
94V-2, 2 Circuits,
Glow-Wire Capable,
Black

7.50mm Pitch Sabre [436803003](#)
Plug Housing, UL
94V-2, 3 Circuits,
Glow-Wire Capable,
Black

7.50mm Pitch Sabre [436803004](#)
Plug Housing, UL
94V-2, 4 Circuits,
Glow-Wire Capable,
Black

7.50mm Pitch Sabre [436803005](#)
Plug Housing, UL
94V-2, 5 Circuits,
Glow-Wire Capable,
Black

7.50mm Pitch Sabre [436803006](#)
Plug Housing, UL
94V-2, 6 Circuits,
Glow-Wire Capable,
Black

This document was generated on 02/10/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION