


1168MQ
Szczypce półokrągłe odgięte o 45°, w izolacji do 1000V

EN 60900

	Art.	L mm	L1 mm	 mm	A mm	B mm	C mm	D mm	L mm	 g
										
011680096	1168MQ 160	160	50	1,6	19	3	2,5	9	164	146
011680100	1168MQ 200	200	70	1,6	20	3,5	3,5	10	205	208

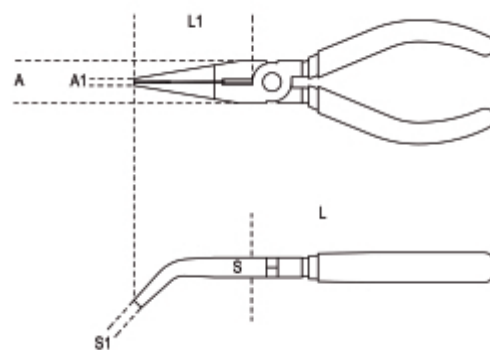

14

Zeskanuj kod QR, aby uzyskać dostęp do zakładki

Specyfikacje, media i dokumentacja dostępne za

