



Surface LED profile **GLS2**

SET: **FIX-GLS2-YY-2m-SET:**


- Profile 2020mm (YY-colors)
- polycarbonate covers - FROST
- endcaps
- clips

Main features:

- excellent heat dissipation
- designed and manufactured in the EU
- easy to install and remove the cover

Application:

- home and shop furniture lighting
- decorative and lighting installations
- for precise detail illumination
- installation in stairs and cavities

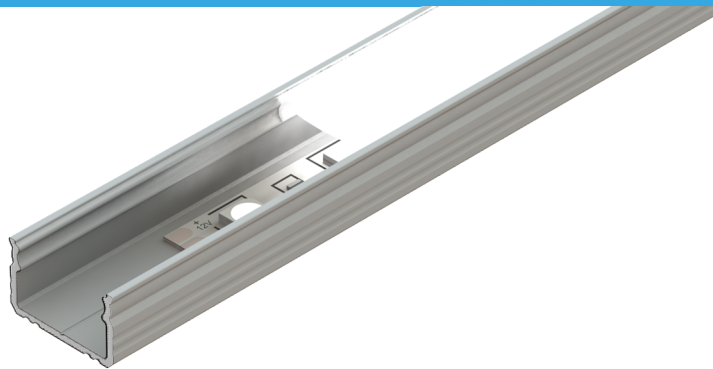


Available colors

-  raw aluminum - **RW**
-  silver anodized - **AS**
-  white powder coated - **LW**
-  black powder coated - **LB**


Additional information

Profile type	surface standard
LED strip width	max. 12mm
Standard lengths	1000mm, 2020mm,
Installation method	brackets, double-sided tape.

Dimensions [mm]:

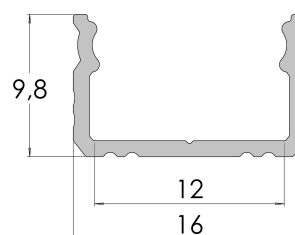


Installation scheme

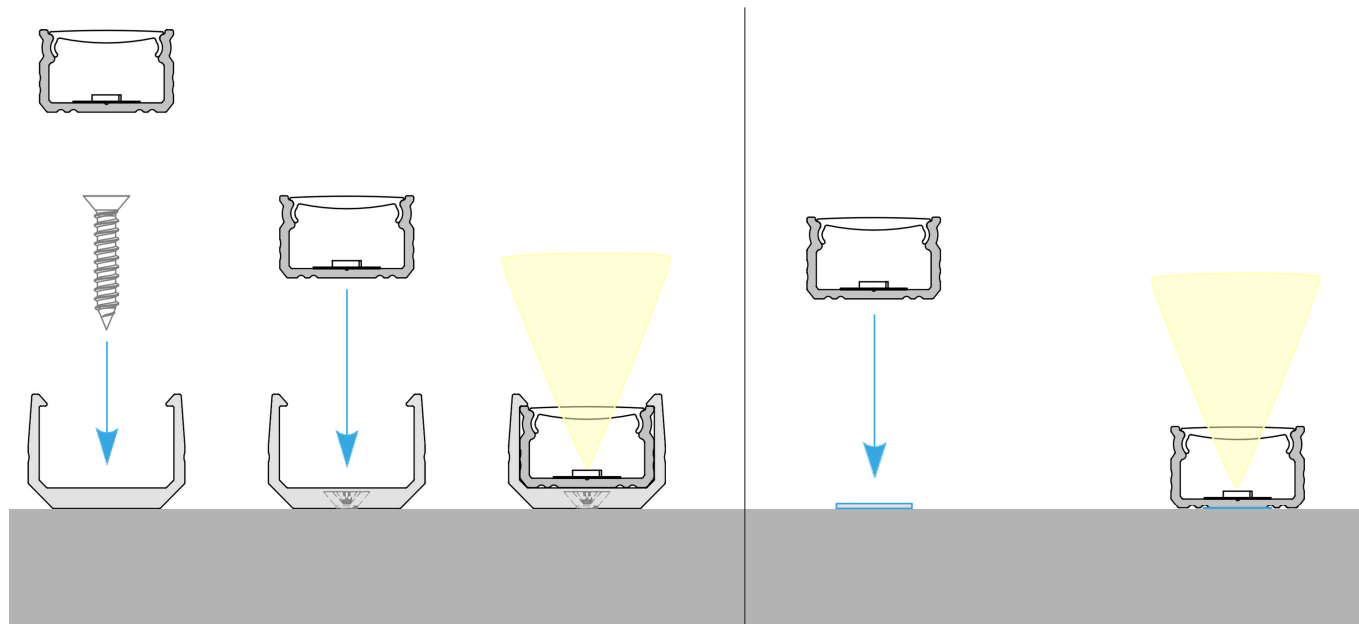

Example of a bracket installation

Example of a double-sided tape installation.

Product code

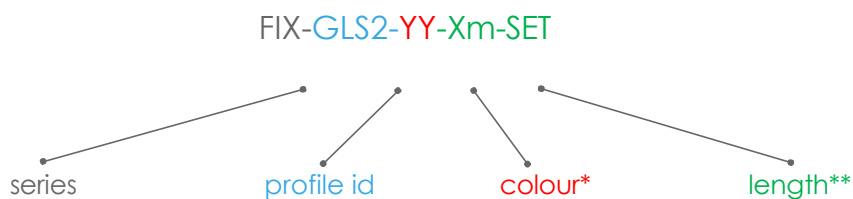

* **AS** - silver anodized, **LB** - black powder coated, **LW** - white powder coated, **RW** - raw aluminum


** **1m** – 1000mm, **2m** – 2020mm,

Available accessories


Professional polycarbonate covers (PC) / light transmittance



PVC covers / light transmittance

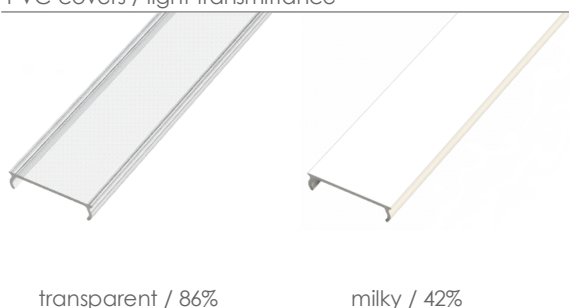


Endcaps

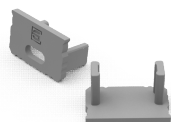

grey, black, white



Clips

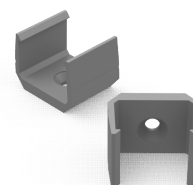

transparent, grey, black, white



Detailed accessory list

AL12-COV-TR-PC-XXXX*	transparent cover PC	AL12-GLS2-AB-EC-O	black endcap with hole
AL12-COV-FR-PC-XXXX	frost cover PC	AL12-GLS2-AB-EC	10sets of black endcaps**
AL12-COV-OP-PC-XXXX	opal cover PC	AL12-GLS2-AB-EC-O	50sets of black endcaps**
AL12-COV-ML-PC-XXXX	milky cover PC	AL12-GLS2-TR-MB	transparent clip
AL12-COV-BL-PC-XXXX	black cover PC	AL12-GLS2-TR-MB-SET10	10sets of transp. clips***
AL12-COV-TR-PVC-XXXX	transparent cover PVC	AL12-GLS2-TR-MB-SET50	50sets of transp. clips***
AL12-COV-ML-PVC-XXXX	milky cover PVC	AL12-GLS-AS-MB	grey clip
AL12-GLS2-AS-EC	grey endcap	AL12-GLS-AS-MB-SET10	10sets of grey clips***
AL12-GLS2-AS-EC-O	grey end cap with hole	AL12-GLS-AS-MB-SET50	50sets of grey clips***
AL12-GLS2-AS-EC-SET10	10sets of grey endcaps**	AL12-GLS-LW-MB	white clip
AL12-GLS2-AS-EC-SET50	50sets of grey endcaps**	AL12-GLS-LW-MB-SET10	10sets of white clips***
AL12-GLS2-LW-EC	white endcap	AL12-GLS-LW-MB-SET50	50sets of white clips***
AL12-GLS2-LW-EC-O	white endcap with hole	AL12-GLS-AB-MB	black clip
AL12-GLS2-LW-EC-SET10	10sets of white endcaps**	AL12-GLS-AB-MB-SET10	10sets of black clips***
AL12-GLS2-LW-EC-O-SET50	50sets of white endcaps**	AL12-GLS-AB-MB-SET50	50sets of black clips***
AL12-GLS2-AB-EC	black endcap		

* **1000** - 1m, **2020** - 2,02m, ** 1set of end caps include: 1x end cap, 1x end cap with hole, *** 1set of clips include: 1x clip, 1x screw