


DIGITUS® Modular High Density Patch Panel, shielded

DN-91424

EAN 4016032343318

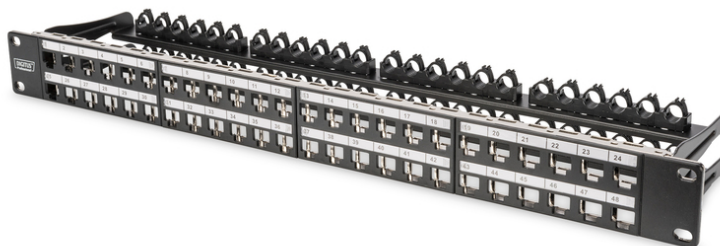

Modular Patch Panel, shielded, 48-port label field, 1U, rack mount, black RAL 9005

The DIGITUS® 48 Port 1U Modular Patch Panel ensures a High Density with the benefit of 48 Keystone Jacks in just one height unit.

- Layout Keystone Entry: Straight
- Area of application: 483 mm (19") cabinet
- Norms: ISO/IEC 11801 3rd Ed., EN 50173-1, EIA/TIA 568-C
- General properties:
- Suitable for 483 mm (19") cabinet mounting
- Suitable for shielded Digitus® Keystone Modules and Couplers
- Central ground connection
- Plastic label field
- Technical properties:
- Housing material: 1.5 mm SPCC cold rolled steel sheet, powder-coated

- Material standard: EN 10 130(1991), BS 1449, NFA 36/401, DIN 1623, UNI 5866, UNE 36-086, SIS, JIS G 3141, ASTM, SAE, NFA 36/401
- Grounding bar material: Galvanized steel
- Physical properties:
- Operation temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Operation temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Colour: Black RAL9005


Attributes

- Color: black, RAL 9005
- Ports: 48
- Units: 1
- Category: CAT 6A

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	15	8.80	53.00	28.00	34.00	50,456.00
Packaging Unit Inside	1	0.59	5.00	53.00	18.00	4,770.00
Packaging Unit Single	1	0.59	5.00	53.00	18.00	4,770.00
Net single without Packaging	1	0.48	5.00	53.00	18.00	4,770.00

More images:

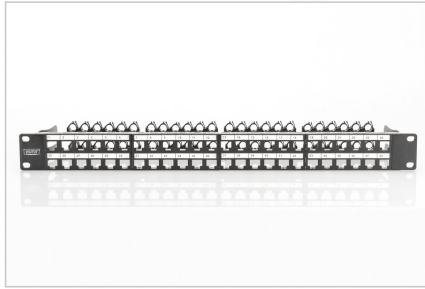

Safety notes

- Protect product from moisture
- Avoid antistatic charging when installing the product
- Observe the specifications of the raw cable manufacturer during installation

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schöffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com