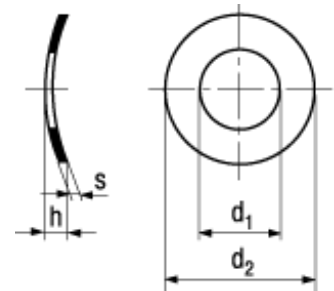


**DIN 137 A**

Norma ritirata

**BN 590****Rosette elastiche**

curvate

Bronzo fosforoso

grezzo

- ~UNI 8840 A
- ~ČSN 021733



Per i nuovi progetti si raccomanda di utilizzare la norma DIN 137 B

| Article# |  | d <sub>1</sub> | d <sub>2</sub> | h min. | s   |
|----------|-----------------------------------------------------------------------------------|----------------|----------------|--------|-----|
| 1227645  | M2                                                                                | 2,2            | 4,5            | 0,5    | 0,3 |
| 1227661  | M2,5 / M2,6                                                                       | 2,8            | 5,5            | 0,55   | 0,3 |
| 1227688  | M3                                                                                | 3,2            | 6              | 0,65   | 0,4 |
| 1227718  | M4                                                                                | 4,3            | 8              | 0,8    | 0,5 |
| 1227726  | M5                                                                                | 5,3            | 10             | 0,9    | 0,5 |
| 1227734  | M6                                                                                | 6,4            | 11             | 1,1    | 0,5 |
| 1227742  | M8                                                                                | 8,4            | 15             | 1,7    | 0,5 |
| 1227750  | M10                                                                               | 10,5           | 18             | 2      | 0,8 |