

Switch RJ45 10 Gbps 2 port manual bidirectional

Description

This RJ45 switch by Delock is a manual bidirectional switch for connecting different devices with RJ45 port, which offers two different applications.

1. Two devices with RJ45 port can be connected alternately to one network.
2. One device with RJ45 port can be connected alternately to two networks.



Item no. 87673

EAN: 4043619876730

Country of origin: China

Package: Retail Box

Technical details

- Connectors: 3 x RJ45 Ethernet jack
- Data transfer rate:
 - Ethernet up to 10 Mbps
 - Fast Ethernet up to 100 Mbps
 - Gigabit Ethernet up to 1000 Mbps
 - 2,5 Gigabit Ethernet up to 2500 Mbps
 - 5 Gigabit Ethernet up to 5000 Mbps
 - 10 Gigabit Ethernet up to 10000 Mbps
- Supports Half / Full Duplex mode
- Supports CAT-5/5e UTP and STP cable
- Supports PoE
- 2 mechanical buttons
- Plastic housing
- No external power supply needed
- Dimensions (LxWxH): ca. 112 x 68 x 29 mm (without button)
- Colour: grey / black


System requirements

- A free network port
- Network connection cables

Package content

- Switch
- User manual

Images

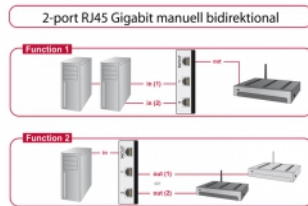

Interface

Connector:	3 x RJ45 jack
------------	---------------

Physical characteristics

Housing material:	Plastic
Length:	112 mm
Width:	68 mm
Height:	29 mm
Colour:	grey black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de