



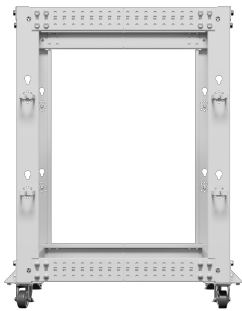

OR01-6115-S

# OPEN RACK 19"

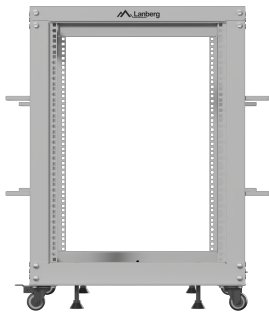

## PRODUCT FEATURES:

- Adjustable installation depth from 576-1033 mm, allowing flexibility to accommodate different equipment and user needs.
- Load capacity of up to 600 kg - Robust construction provides exceptional durability, ideal for professional applications.
- Durable, well-thought-out design - Stable frame made of high-quality steel for long-lasting use and reliability.
- Stand equipped with feet, casters with brakes and cable holders.

## PRODUCT SPECIFICATION:

Type of cabinet	Open Rack
Size	19",
ICT height	15 U
Assembly type	Self-assembly
Mounting depth range	from 576,4 up to 1 033,6 mm
Maximum static load	600 kg
Number of vertical rails	4
Colour	Gray
RAL color	RAL7035
Mounting rails thickness	2 mm
Frame thickness	2 mm
Other elements sheet thickness	2 mm
Depth	657 mm
Width	600 mm
Height	844 mm
Height without casters	774 mm
Weight	22 kg
Standard	ANSI/EIA RS-310-D
Grounding Details	Frame
Included Accessories	User Manual, Wheels with brake, Legs, M6 screws