


LED tape K-BT-1490-24 14.9 W/m, IP20

Ref. K-BT-1490-24

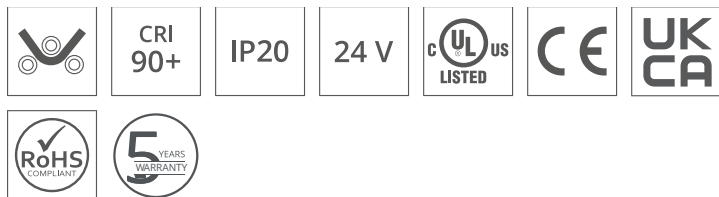

TECHNICAL SPECIFICATIONS

IP protection rating	20
CRI	90
LxBy	L80B50
Lifetime	61000 h
Possibility of bending	yes
Input voltage	24 V DC
Power consumption	14.9 W/m
Beam angle	120°
MacAdam's ellipse	3 SDCM
Number of LEDs per 1 m	196
Number of LEDs per cut section	6 pcs
Warranty [months]	60

Color temperature	Lumen output	Efficiency	Ref
2700 K	1270 lm/m	85 lm/W	K-BT27-1490-24
3000 K	1305 lm/m	88 lm/W	K-BT30-1490-24
4000 K	1520 lm/m	102 lm/W	K-BT40-1490-24