




Price* : 67.11 GBP

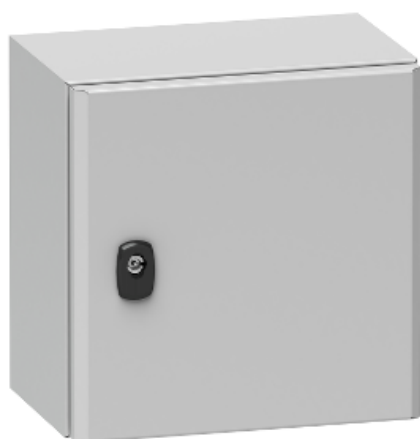

Main

Range	Spacial
Product name	Spacial S3D
Application	Multi-purpose
Category	Compact enclosure
Enclosure nominal height	400 mm
Enclosure nominal width	300 mm
Enclosure nominal depth	200 mm
Door type	Plain
Mounting plate description	Plain
Type of gland plate	Standard
Installation accessory type	Wall-mounting
Device composition	Body 1 Mounting plate 1 Door with lock 1 Cable gland plate 1

Complementary

Body type	Single piece body Gutter-shaped front rail double sheet thickness
Number of doors	1 front face
Door opening side	Reversible 120 °
Lock type	3 mm double-bar lock
Accessibility for operation	Front
Removable parts	Door by hinges Cable gland plate by screws Mounting plate by fixing element
Material	Galvanised steel for mounting plate Steel for enclosure
Surface finish	Epoxy-polyester powder enclosure

Colour	Grey RAL 7035 enclosure :
Standards	IEC 62208
Product certifications	DNV BV UL GL LR CUL
Product weight	6.9 kg

Environment

IP degree of protection	IP66 conforming to IEC 60529
IK degree of protection	IK10 conforming to IEC 62262

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0810 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
Product environmental profile	Available  Product Environmental Profile
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months 18 months
-----------------	---------------------