


FERRITE CORES – SOLID FERRITE CORES

RT Toroid Cores

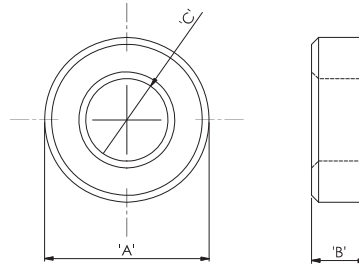

Ferrite Material: K5B RMS-303						
RT	A (mm)	B (mm)	C (mm)	Impedance (Ω)		Standard Pack (Pieces)
				25MHz	100MHz	
RT-30-10-20-K5B	3	2	1	20	42	4.000
RT-30-12-20-K5B	3	2	1.2	17	38	4.000
RT-35-8-25-K5B	3.5	3	1	25	52	4.000
RT-35-8-30-K5B	3.5	3	0.8	31	53	4.000
RT-35-10-30-K5B	3.5	3	1.0	29	50	4.000
RT-35-12-30-K5B	3.5	3	1.2	25	45	4.000
RT-35-13-30-K5B	3.5	3	1.3	26	47	4.000
RT-35-13-33-K5B	3.5	3.25	1.3	27	48	4.000
RT-35-14-30-K5B	3.5	3	1.4	22	48	4.000
RT-35-14-33-K5B	3.5	3	1.4	26	49	4.000
RT-35-15-15-K5B	3.5	1.54	1.5	15	36	4.000
RT-35-15-30-K5B	3.5	3	1.5	21	42	4.000
RT-35-15-33-K5B	3.5	3.3	1.5	21	43	4.000
RT-35-17-30-K5B	3.5	3	1.7	17	38	4.000
RT-35-18-13-K5B	3.5	1.3	1.8	11	31	4.000
RT-35-18-30-K5B	3.5	3	1.8	18	37	4.000
RT-39-23-25-K5B	3.94	2.54	2.29	15	36	4.000
RT-40-15-20-K5B	4	2	1.5	19	39	4.000
RT-40-15-30-K5B	4	3	1.5	23	45	4.000
RT-40-20-15-K5B	4	1.5	2	13	35	4.000
RT-40-20-20-K5B	4	2	2	14	37	4.000
RT-40-20-30-K5B	4	3	2	20	41	4.000
RT-40-22-17-K5B	4	1.7	2.2	12	31	4.000
RT-41-16-40-K5B	4.1	4	1.6	31	55	2.000
RT-43-28-25-K5B	4.3	2.5	2.8	13	35	4.000
RT-44-28-14-K5B	4.4	1.4	2.8	12	32	5.000
RT-45-25-32-K5B	4.5	3.2	2.5	18	37	4.000
RT-50-15-40-K5B	5	4	1.5	30	51	2.000
RT-50-20-20-K5B	5	2	2	17	37	2.000
RT-50-20-40-K5B	5	4	2	30	46	2.000
RT-50-23-30-K5B	5	3	2.3	19	39	2.000
RT-60-30-15-K5B	6	1.5	3	10	31	2.000
RT-60-30-20-K5B	6	2	3	15	35	2.000
RT-60-30-30-K5B	6	3	3	21	40	2.000
RT-60-30-38-K5B	6	3.8	3	22	43	1.000
RT-60-30-40-K5B	6	4	3	24	44	1.000
RT-60-30-55-K5B	6	5.5	3	31	51	1.000
RT-65-43-60-K5B	6.5	6	4.3	21	42	1.000
RT-70-35-40-K5B	7	4	3.5	23	46	1.000
RT-70-35-60-K5B	7	6	3.5	34	59	1.000
RT-73-33-43-K5B	7.3	4.3	3.3	27	50	1.000
RT-75-24-40-K5B	7.5	4	2.4	32	62	1.000

Standard Pack sizes may vary

FERRITE CORES – SOLID FERRITE CORES

Ferrite Material: K5B RMS-303						
RT	A (mm)	B (mm)	C (mm)	Impedance (Ω)		Standard Pack (Pieces)
				25MHz	100MHz	
RT-76-52-62-K5B	7.6	6.2	5.2	21	40	1.000
RT-79-40-70-K5B	7.9	7	4	33	57	500
RT-80-31-40-K5B	8	4	3.1	33	52	1.000
RT-80-40-30-K5B	8	3	4	17	37	1.000
RT-80-40-40-K5B	8	4	4	23	46	1.000
RT-80-40-60-K5B	8	6	4	33	57	500
RT-80-60-50-K5B	8	5	6	15	36	500
RT-80-60-70-K5B	8	7	6	20	42	500
RT-85-50-30-K5B	8.5	3	5	16	34	1.000
RT-90-50-30-K5B	9	3	5	16	37	1.000
RT-90-50-80-K5B	9	8	5	38	64	500
RT-93-45-64-K5B	9.3	6.35	4.5	32	50	500
RT-94-63-72-K5B	9.4	7.2	6.3	22	42	1.000
RT-95-46-46-K5B	9.5	4.57	4.6	27	47	500
RT-95-48-33-K5B	9.5	3.3	4.8	22	45	1.000
RT-95-50-48-K5B	9.5	4.8	5	22	47	500
RT-95-50-50-K5B	9.5	5	5	26	49	500
RT-100-30-60-K5B	10	6	3	50	82	500
RT-100-50-50-K5B	10	5	5	34	73	500
RT-100-60-30-K5B	10	3	6	15	37	1.000
RT-100-60-40-K5B	10	4	6	20	42	1.000
RT-100-60-50-K5B	10	5	6	22	41	500
RT-100-60-62-K5B	10	6.2	6	25	49	500
RT-100-60-80-K5B	10	8	6	33	60	500
RT-100-70-50-K5B	10	5	7	17	39	500
RT-100-70-70-K5B	10	7	7	22	44	500
RT-100-70-75-K5B	10	7.5	7	25	46	500
RT-103-58-102-K5B	10.3	10.2	5.8	40	67	500
RT-110-50-90-K5B	11	9	5	60	107	200
RT-120-60-40-K5B	12	4	6	24	48	500
RT-120-60-60-K5B	12	6	6	34	58	500
RT-120-60-80-K5B	12	8	6	46	77	500
RT-120-70-55-K5B	12	5.5	7	26	49	500
RT-120-70-60-K5B	12	6	7	28	48	500
RT-125-80-64-K5B	12.5	6	8	24	46	500
RT-125-80-120-K5B	12.5	12	8	36	58	200
RT-127-79-64-K5B	12.7	6.35	7.9	26	68	500
RT-130-70-30-K5B	13	3	7	17	39	500
RT-130-70-55-K5B	13	5.5	7	27	50	300
RT-130-70-60-K5B	13	6	7	28	51	500
RT-130-70-70-K5B	13	7	7	32	56	200
RT-130-71-127-K5B	13	12.7	7.1	60	106	200
RT-140-80-50-K5B	14	5	8	26	50	500
RT-140-80-70-K5B	14	7	8	28	50	500
RT-140-90-50-K5B	14	5	9	19	37	500
RT-142-64-102-K5B	14.2	10.16	6.35	57	95	200
RT-142-64-135-K5B	14.2	13.5	6.35	75	125	200
RT-142-80-120-K5B	14.2	12	8	49	76	200
RT-145-102-80-K5B	14.5	8	10.2	29	69	200
RT-150-105-120-K5B	15	12	10.5	37	62	200
RT-159-79-143-K5B	15.88	14.27	7.87	79	121	100
RT-160-80-120-K5B	16	12	8	59	95	200
RT-160-80-130-K5B	16	13	8	64	99	100
RT-160-90-120-K5B	16	12	9	55	87	200
RT-160-100-70-K5B	16	7	10	32	71	300
RT-160-100-80-K5B	16	8	10	29	55	200
RT-160-100-100-K5B	16	10	10	43	85	150
RT-160-120-80-K5B	16	8	12	26	48	200
RT-160-120-150-K5B	16	15	12	33	58	200
RT-165-82-130-K5B	16.5	13	8.2	70	125	120
RT-165-82-160-K5B	16.5	16	8.2	83	140	120
RT-165-92-75-K5B	16.5	7.5	9.2	35	70	200
RT-175-80-100-K5B	17.5	10	8.0	62	94	98
RT-175-95-50-K5B	17.5	5	10	22	44	200
RT-175-95-64-K5B	17.5	6	9.5	31	53	200
RT-175-95-70-K5B	17.5	7	9.5	30	54	200
RT-175-95-110-K5B	17.5	11	9.5	55	96	200
Standard Pack sizes may vary						




FERRITE CORES — SOLID FERRITE CORES


Ferrite Material: K5B RMS-303						
RT	A (mm)	B (mm)	C (mm)	Impedance (Ω)		Standard Pack (Pieces)
				25MHz	100MHz	
RT-175-95-127-K5B	17.5	13	9.5	59	95	100
RT-175-95-135-K5B	17.5	14	9.5	63	115	100
RT-175-95-150-K5B	17.5	15	9.5	70	113	112
RT-175-107-80-K5B	17.5	8	10.7	33	60	200
RT-180-100-60-K5B	18	6	10	31	55	200
RT-180-100-100-K5B	18	10	10	47	77	200
RT-180-100-150-K5B	18	15	10	69	123	100
RT-187-102-143-K5B	18.67	14.27	10.16	70	119	100
RT-187-102-170-K5B	18.67	17.02	10.16	75	125	100
RT-190-100-100-K5B	19	10	10	54	102	100
RT-190-120-80-K5B	19	8	12	32	72	200
RT-190-120-100-K5B	19	10	12	37	78	100
RT-200-100-50-K5B	20	5	10	28	68	140
RT-200-100-80-K5B	20	8	10	38	62	100
RT-200-100-100-K5B	20	10	10	50	82	100
RT-200-120-100-K5B	20	10	12	40	68	84
RT-205-102-100-K5B	20.5	10	10.2	53	86	80
RT-212-127-60-K5B	21.2	6	12.7	27	52	200
RT-220-135-64-K5B	22	6.35	13.5	28	53	200
RT-220-135-80-K5B	22	8	13.5	37	78	100
RT-220-140-65-K5B	22	7	14	28	68	84
RT-220-140-80-K5B	22	8	14	33	73	100
RT-220-140-100-K5B	22	10	14	42	90	84
RT-220-140-120-K5B	22	12	14	40	85	84
RT-221-137-127-K5B	22.1	12.7	13.72	48	83	100
RT-225-138-64-K5B	22.5	6.4	13.8	25	47	200
RT-225-138-127-K5B	22.5	12.7	13.8	46	71	50
RT-230-135-64-K5B	23	6.35	13.5	28	53	200
RT-236-114-140-K5B	23.6	14	11.4	80	133	60
RT-236-150-60-K5B	23.6	6	15	26	70	72
RT-236-150-114-K5B	23.6	11	15	43	85	100
RT-250-150-80-K5B	25	8	15	38	79	100
RT-250-150-100-K5B	25	10	15	44	87	50
RT-250-150-120-K5B	25	12	15	53	97	60
RT-250-150-150-K5B	25	15	15	61	105	60
RT-254-127-64-K5B	25.4	6.35	12.7	39	80	100
RT-259-128-213-K5B	25.91	21.3	12.8	106	174	40
RT-260-130-127-K5B	26	12.7	13	74	125	50
RT-280-160-75-K5B	28	7.5	16	33	59	100
RT-280-160-130-K5B	28	13	16	55	100	50
RT-280-160-170-K5B	28	17	16	71	120	50
RT-280-160-200-K5B	28	20	16	85	155	40
RT-290-190-75-K5B	29	7.50	19	26	70	100
RT-290-190-77-K5B	29	7.7	19	33	76	50
RT-290-190-138-K5B	29	13.8	19	46	94	40
RT-310-190-70-K5B	31	7	19	35	77	40
RT-310-190-80-K5B	31	8	19	30	55	40
RT-310-190-160-K5B	31	16	19	68	115	40
RT-310-190-222-K5B	31	22	19	88	146	32
RT-360-250-70-K5B	36	7	25	23	63	36
RT-360-250-127-K5B	36	13	25	39	84	24
RT-406-274-150-K5B	40.6	15	27.4	55	106	18
RT-594-348-128-K5B	59.4	12.8	34.8	58	118	10

Standard Pack sizes may vary


RT-30-10-20-K5B

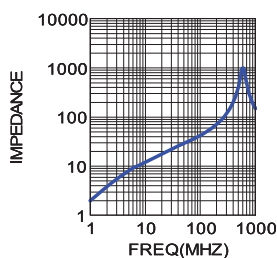


RT-30-12-20-K5B

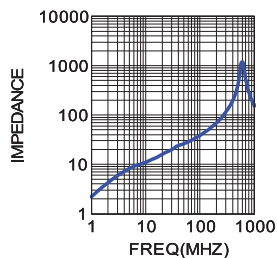

RT-35-8-25-K5B

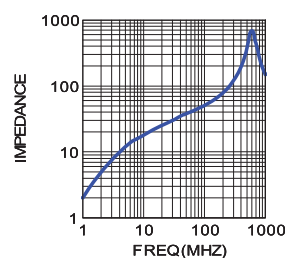

RT-35-8-30-K5B

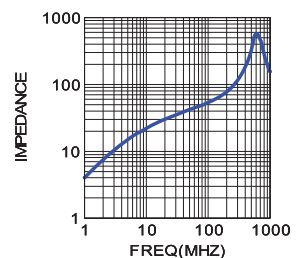


All the data listed in this catalogue are reference only,
Richco reserves the right to alter or revise the specifications without prior notification

Richco - dedicated to superior quality, for demanding quality standards




FERRITE CORES – SOLID FERRITE CORES

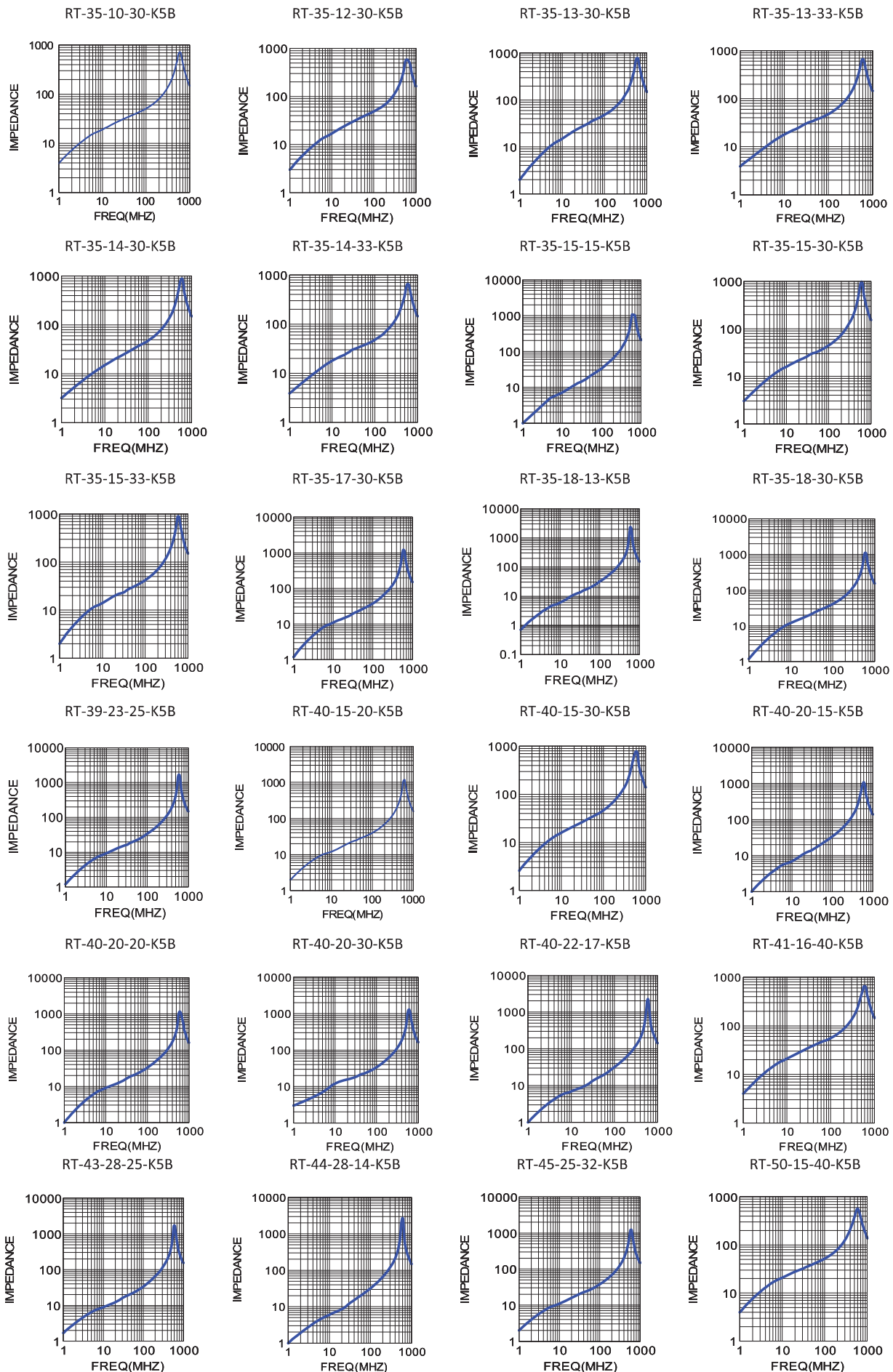


All the data listed in this catalogue are reference only,
Richco reserves the right to alter or revise the specifications without prior notification

FERRITE CORES – SOLID FERRITE CORES

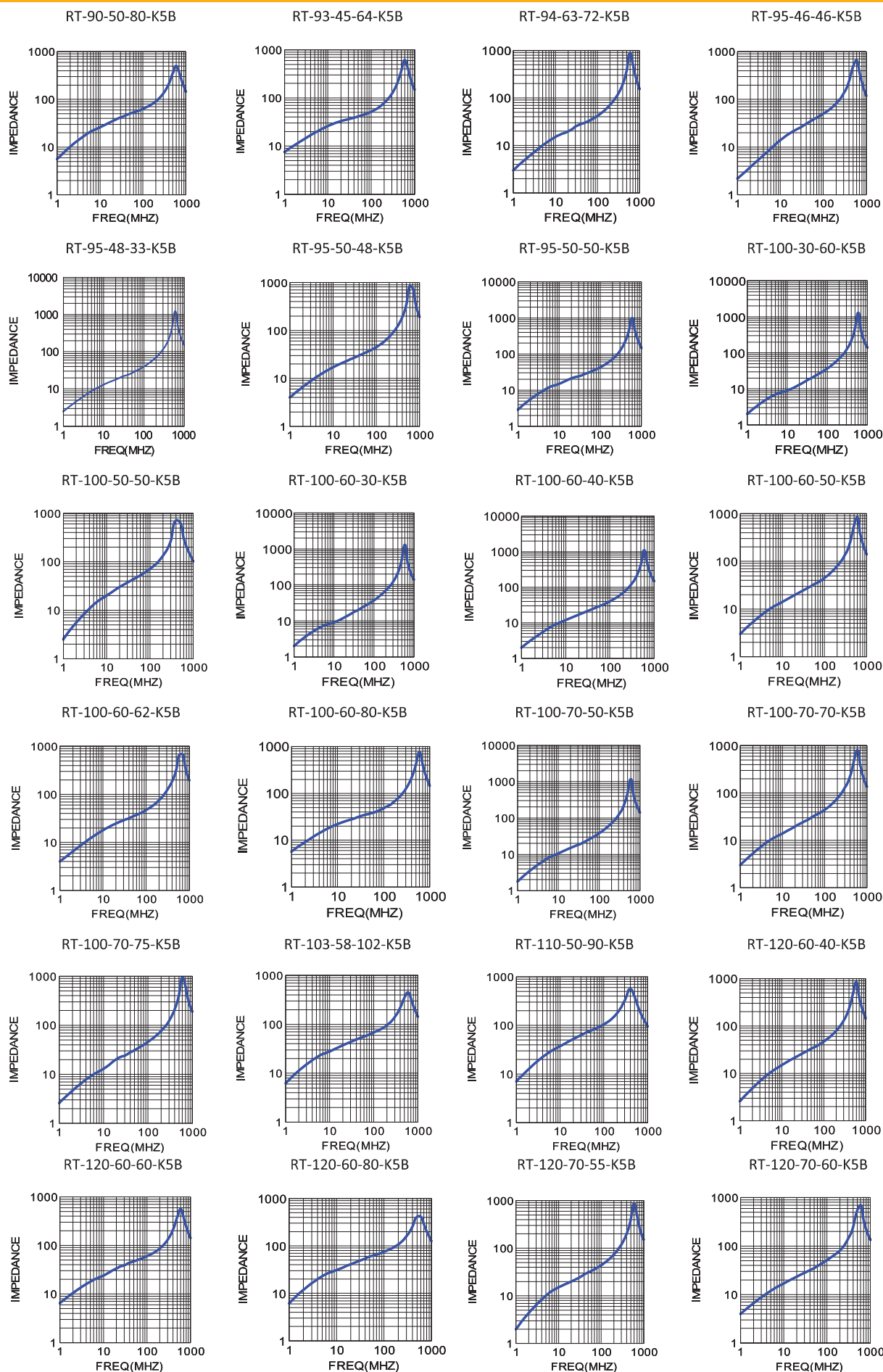

All the data listed in this catalogue are reference only,
Richco reserves the right to alter or revise the specifications without prior notification

FERRITE CORES — SOLID FERRITE CORES

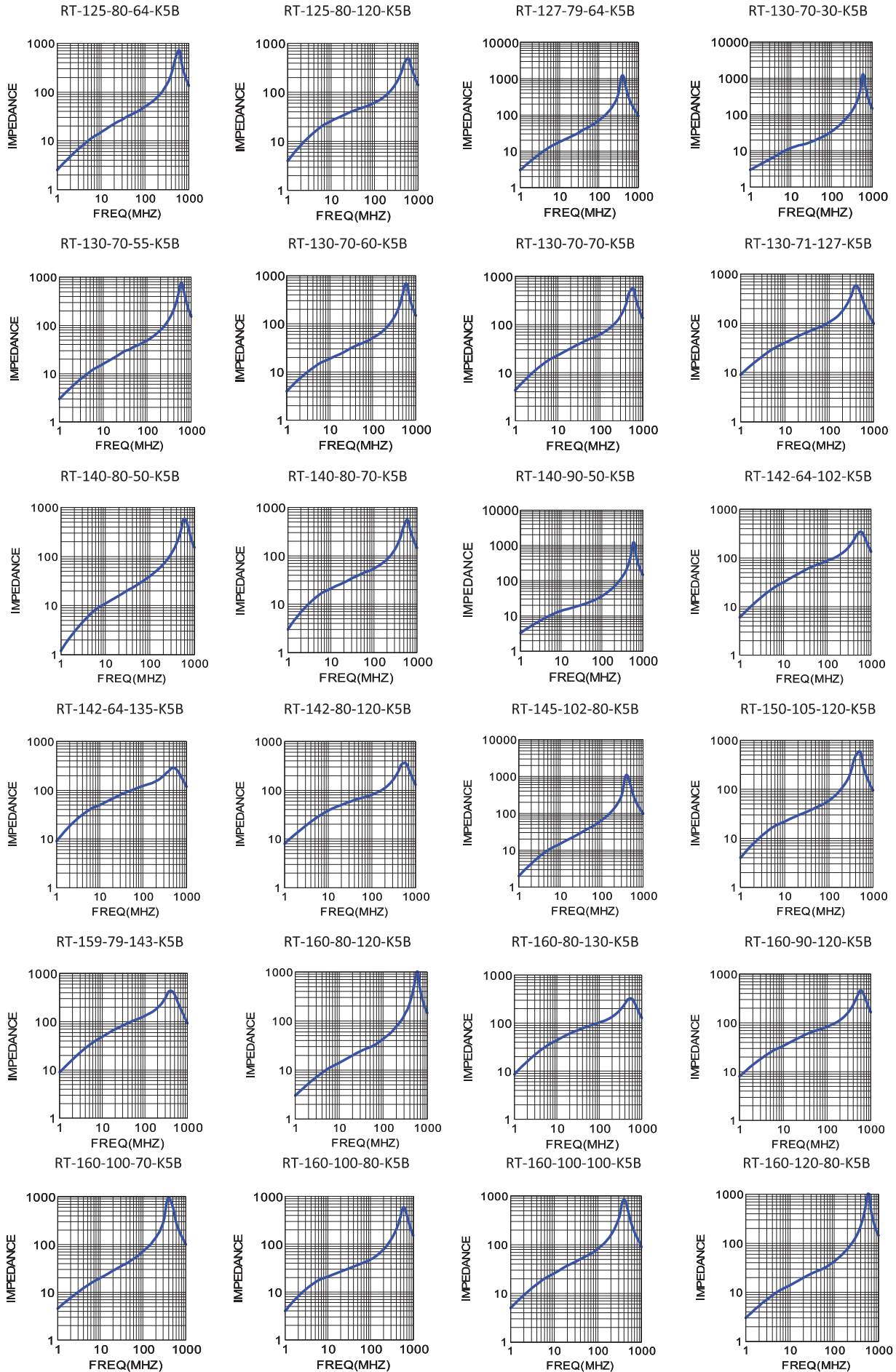


All the data listed in this catalogue are reference only,
Richco reserves the right to alter or revise the specifications without prior notification

Quality products you need, when you need them




FERRITE CORES — SOLID FERRITE CORES

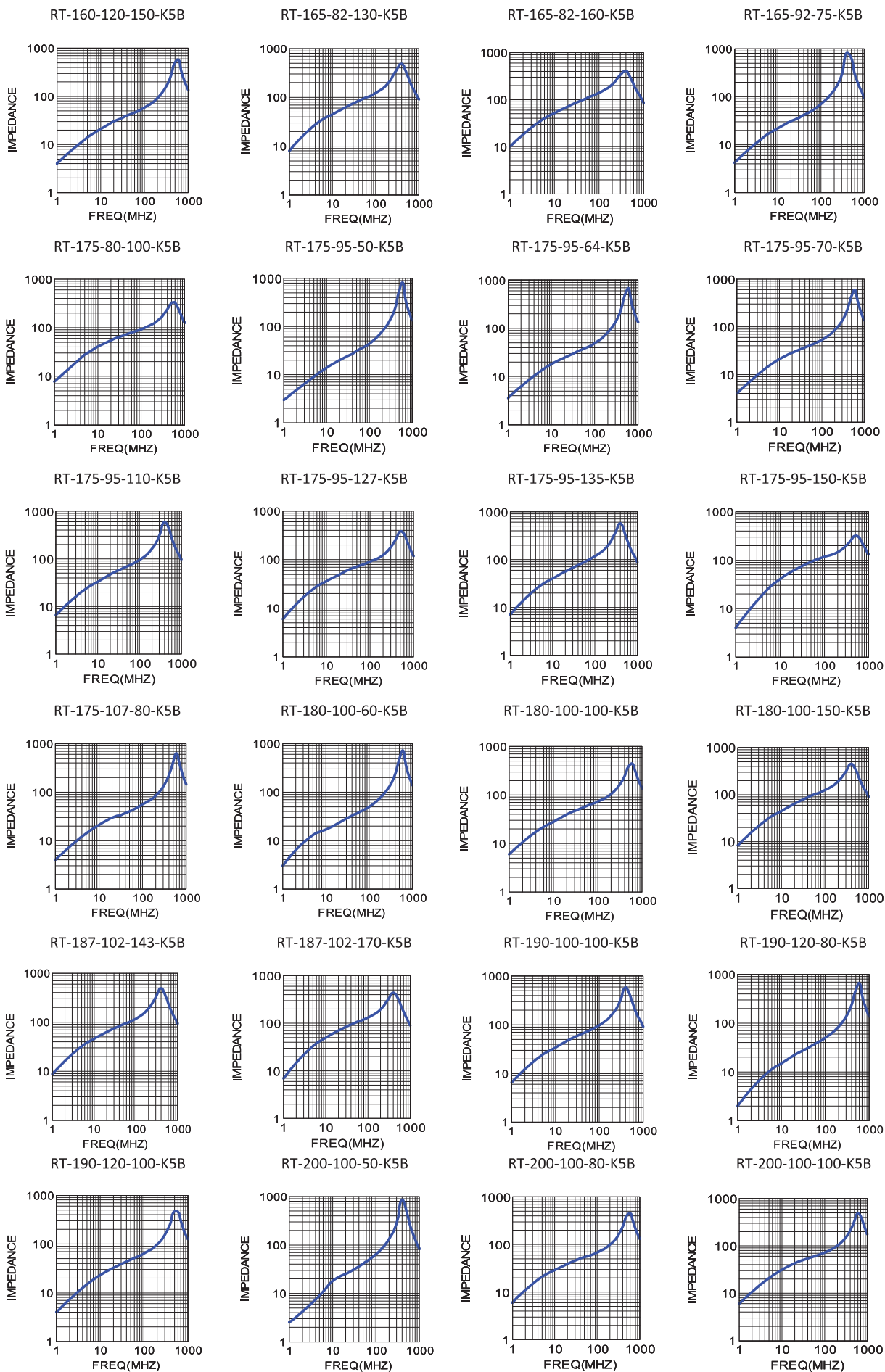

All the data listed in this catalogue are reference only,
Richco reserves the right to alter or revise the specifications without prior notification


FERRITE CORES — SOLID FERRITE CORES

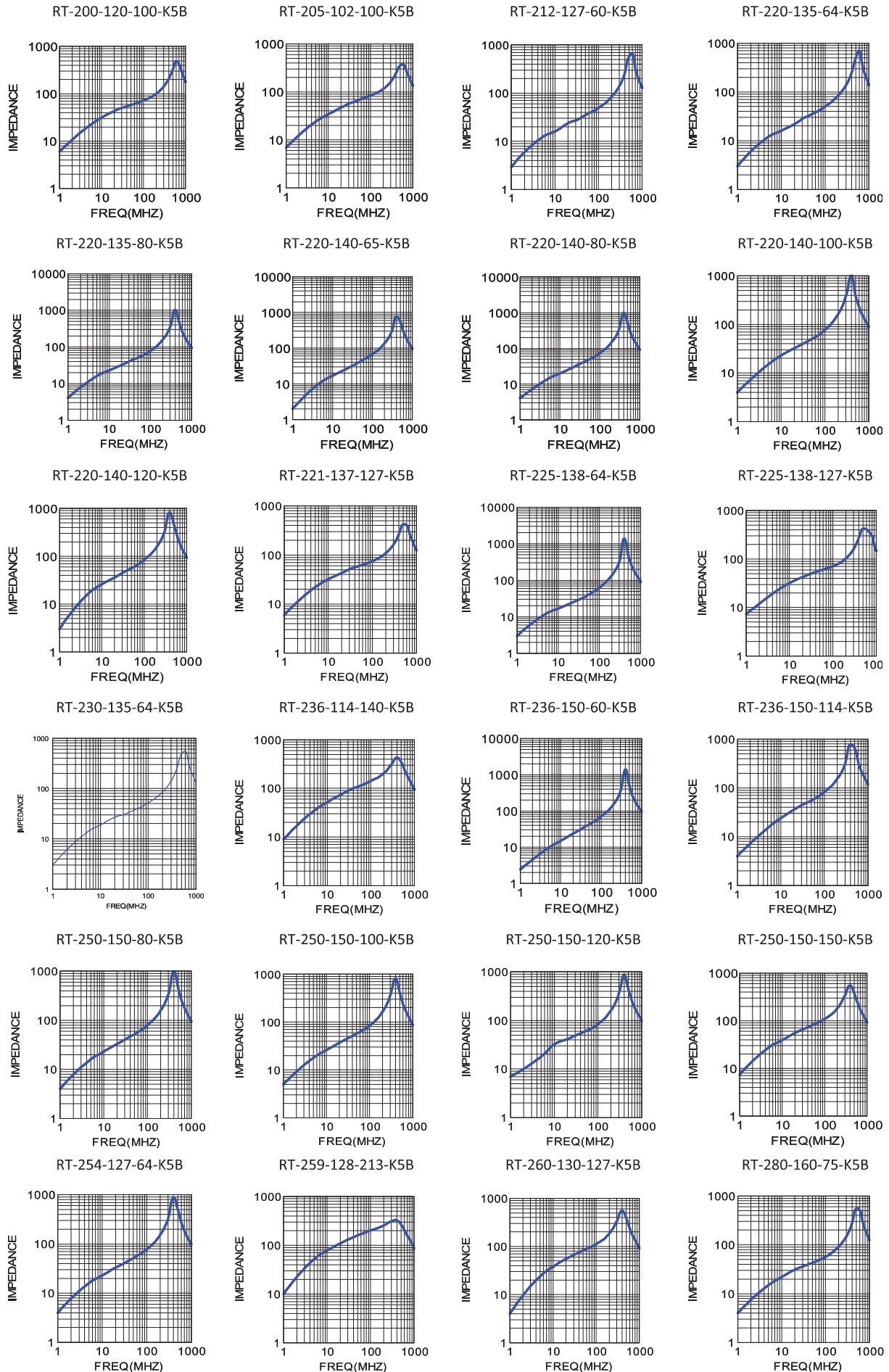

All the data listed in this catalogue are reference only, Richco reserves the right to alter or revise the specifications without prior notification

Can't find a part, call us and use our extensive custom design service

FERRITE CORES — SOLID FERRITE CORES

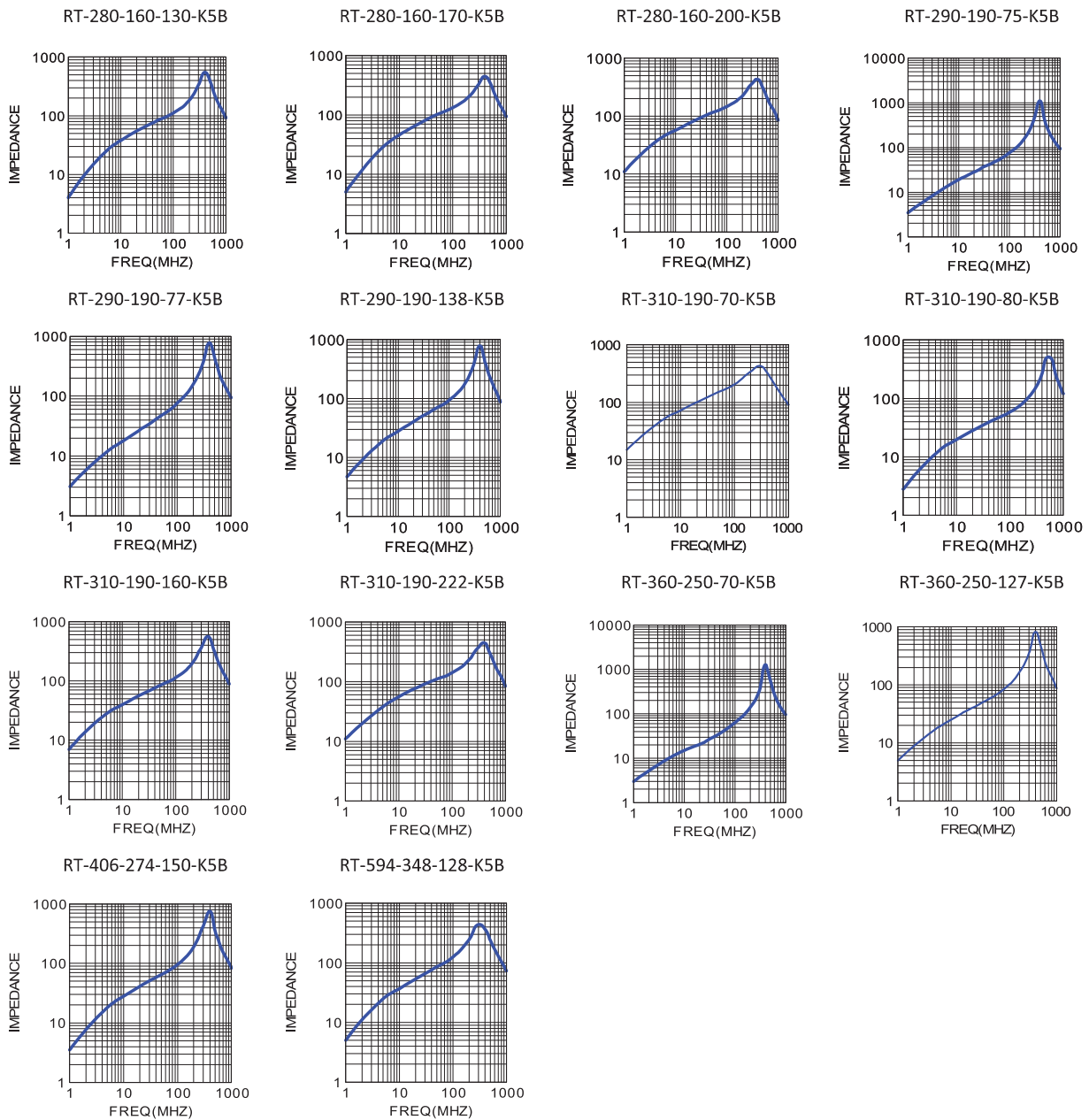

Notes
