

DIGITUS® Modular patch panel, 24-port

DN-91411

EAN 4016032280798



Modular Patch Panel, shielded 24-port, blank, 1U, rack mount, black RAL 9005

The modular patch panel from DIGITUS® is available as a 16- or 24-port version. The 1.5 mm cold-rolled carbon steel provides optimum support for your Keystone modules.

- Keystone mount version: Straight
- Application areas: 483 mm (19") distribution cabinet
- Standards: ISO/IEC 11801 3rd Ed., EN 50173-1, EIA/TIA 568-C.2
- General properties:
- Suitable for 483 mm (19") rack mounting
- Suitable for shielded Digitus® Keystone modules and connectors
- Central earthing connection
- Technical features:

- Housing material: 1.5 mm SPCC cold-rolled sheet steel, powder-coated
- Material standard: EN 10 130(1991), BS 1449, NFA 36/401, DIN 1623, UNI 5866, UNE 36-086, SIS, JIS G 3141, ASTM, SAE, NFA 36/401
- Material earthing bar: galvanized steel
- Physical properties:
- Operating temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Color: Black RAL9005


Attributes

- Color: black, RAL 9005
- Ports: 24
- Units: 1

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	15	13.10	57.00	52.00	26.00	77,064.00
Packaging Unit Inside	1	0.87	7.50	56.00	10.00	4,200.00
Packaging Unit Single	1	0.87	7.50	56.00	10.00	4,200.00
Net single without Packaging	1	0.78	7.50	56.00	10.00	4,200.00

More images:

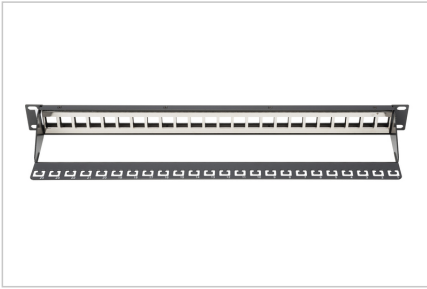

Safety notes

- Protect product from moisture
- Avoid antistatic charging when installing the product
- Observe the specifications of the raw cable manufacturer during installation

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schöffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com