



BETA 1201INOX-E

Screwdrivers for slotted head screws, made from stainless steel

Certifications and Standards

- ISO 2380

Features

The Beta Evox INOX improves every professional's work thanks to its comfortable and secure grip even during longer work sessions.

CORROSION RESISTANCE

The use of AISI 420 stainless steel protects the screwdriver from the action of moisture, chemicals and the weather. Even after long periods of use in critical environments, the material does not oxidise or degrade, maintaining full functional integrity.

CONSTANT MECHANICAL BEHAVIOUR

This screwdriver guarantees a stable response to twisting and stress, thanks to the good hardness and balanced elasticity of the material.


UNRIVALLED COMFORT

For those who work for long periods, comfort is paramount. The Beta Evox screwdriver has a bimaterial handle coated with a layer of high-quality thermoplastic rubber that offers an ergonomic, secure and non-slip grip. This design reduces fatigue during prolonged use, allowing you to work more efficiently without sacrificing comfort.



STAINLESS STEEL BLADE

The proven Beta stainless steel blades offer elasticity, hardness and wear resistance at the top of the professional screwdriver category.

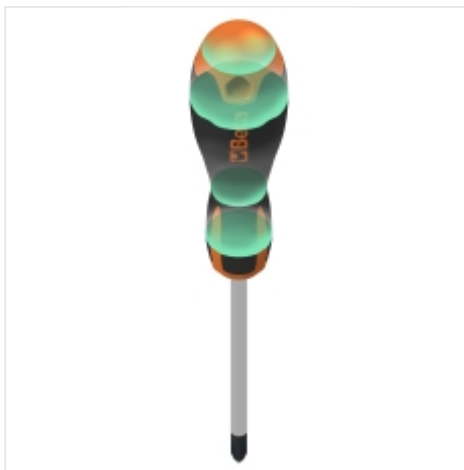

ERGONOMIC DESIGN

The large contact surface allows maximum force to be transmitted with minimum effort.



Anti-roll design

The octagonal cross-section prevents annoying rolling on the work surface.

Dimensions



Certifications and Standards

ISO 2380

Coded items

	Art.	SxAxL mm	L1 mm	Ø mm
012011403	1201INOX-E 2,5X50	0,4x2,5x50	148	2,5
012011409	1201INOX-E 3X75	0,5x3x75	173	3,0
012011430	1201INOX-E 4X100	0,8x4x100	198	4,0
012011442	1201INOX-E 5,5X150	1x5,5x150	259	5,0
012011451	1201INOX-E 6,5X150	1,2x6,5x150	270	6,5

Scan the QR Code to access the web tab
Specs, media and documentation in one click.

