


article#	0359-6
article description	CEE-plug 60A 4P5W 6h IP69k UL
description long	CEE-plug 60A 4P5W 6h IP69k UL (PCE560P6W) housing material: PA6 rated current: 60A number of poles: 4P5W (5p) clock position: 6h rated voltage: 200/346 - 240/415VAC contacts: brass nickel plated connection technology: frame terminals with screws IP rating: IP6X, X6, X7, X9k (watertight) UL type: 4, 4X HP-rating (locked rotor): 10 according to UL1682 and IEC/EN 60309-2 (SERIES II) UL-product category: QLHN / QLHN7 UL-file number: E232901
GTIN (EAN)	9003399608872
country of origin	AT
customs number	85366990
net weight	0.697 kg
packaging quantity	2
minimum order quantity	2

ETIM 10.0	EC000140
Amperage according to UL/CSA (for UL-version)	60 A
Number of poles	5
Voltage according to EN 60309-2	Other
Clock hour position	6 h
Identification colour	Red
Degree of protection (IP)	IP69K
Connection system	Screwed terminal
Cable entry	Gland nut
Suitable for cable diameter	15 – 37 mm
Angle of plug	Straight
Material	Plastic
Contact material	CuZn
Surface treatment contacts	Nickel-plated

a	10.24 inch
b	4.53 inch
K (cable Ø)	0.59-1.46 inch
SW	2.44 inch
wire flexible	10-4 AWG
contact screws	17.7 lbf-in
housing screws	17.7 lbf-in
strain relief	nut 66 lbf-in / clamp 14.2 lbf-in
dismantling length	3.94 inch
stripping length	0.59-0.71 inch
temperature resistance	-13 – 176 °F

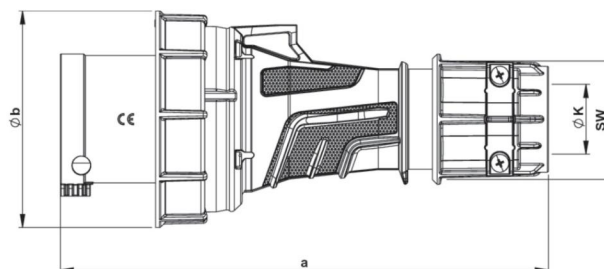

<https://www.pcelectric.at/shop/en/?func=detail&artnr=0359-6>