

Adapter USB Type-C™ > 1 x Serial DB9 RS-232 + Adapter DB25

Description

This adapter by Delock enables the connection of a serial device via a USB Type-C™ port.



Item no. 62904

EAN: 4043619629046

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - Cable:
 - 1 x USB Type-C™ male >
 - 1 x serial RS-232 DB9 male with screws
 - Adapter:
 - 1 x serial RS-232 DB9 female with nuts >
 - 1 x serial RS-232 DB25 male with screws
- Chipset: FTDI FT232RL
- Data transfer rate up to 921.6 Kbps
- Screw type: #4-40 UNC
- Signals: TxD, RxD, RTS, CTS, DTR, DSR, DCD, RI, GND
- Parity: even, odd, none, mark, space
- Stop bits: 1, 2
- Databits: 7, 8
- Flow control: none, Xon / Xoff, RTS / CTS
- FIFO: 128 Byte - RX
- FIFO: 256 Byte - TX
- Colour: black / grey
- Cable length: ca. 1.8 m


System requirements

- Linux Kernel 2.6.31 or above
- Windows 7/7-64/8.1/8.1-64/10/10-64/11
- PC or laptop with a free USB Type-C™ or Thunderbolt™ 3 port

Package content

- Adapter cable USB Type-C™ to 1 x serial
- Adapter DB9 to DB25
- Driver CD
- User manual

Images

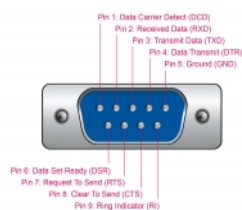

General

Supported operating system:	Linux Kernel 2.6.38 or above MAC OS 10.12.3 Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows 11
-----------------------------	--

Interface

Output:	1 x Serial RS-232 DB9 male
Input:	1 x USB Type-C™ male

Technical characteristics

Chipset:	FTDI 232R
Data transfer rate:	1 Mbps
FIFO:	512 Byte

Physical characteristics

Cable length:	1.8 m
---------------	-------

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de