




Fibre optic through-beam sensor

FE-00-P-A-R3

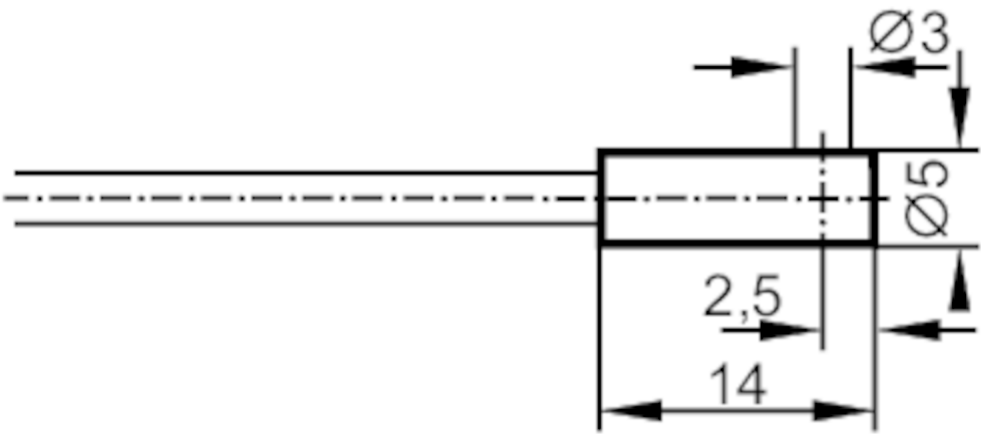

Application		
Design	90° deflection of the light beam	
Function principle	Through-beam sensor	
Application	For use in industrial environments	
Detection zone		
Range with fibre-optic amplifier type	OKF; OUF; OOF	
OKF		
Range of fibre optics	[mm]	120
OOF		
Range of fibre optics	[mm]	400
OUF		
Range of fibre optics	[mm]	120
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	54.5
Version of sensing head	angled	
Sensing head diameter	[mm]	5
Total length	[mm]	600

E20228



Fibre optic through-beam sensor

FE-00-P-A-R3

Min. bending radius	[mm]	20
Fibre arrangement		
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC
Accessories		
Items supplied		E20104
Remarks		
Pack quantity		1 pcs.