



# LogiLink®

## Wireless Presenter

2.4 GHz

Art. No.: ID0218



## Make Your Presentation Unique

Designed to keep people engaged. From the boardroom or classroom, control your presentation while helping your audience follow what you're saying.



Windows & Mac OS Support



Up to 50 m Wireless Range



Air Mouse Control




Digital Pointer



Support PPT/ Video Modes



Plug & Play for USB-A/USB-C

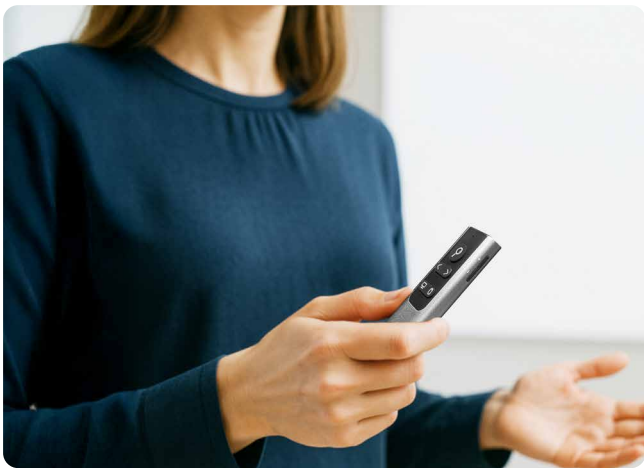

## Multi-functional Controls

The intuitive 8-button design, with the option to black the display out, you can go full screen or switch windows when needed. Effortlessly focus on what matters to your audience.

VIDEO Mode (Play/Pause, Volume and Mute)

PPT Mode (Next, Back, Laser and Black screen)

Quick recharging thru USB-C port



Highlight, Magnify, Digital pointer

Page up/down

Start, stop, black screen



Activity LED

Volume control

Air mouse/annotation

Aluminum housing

LogiLink®

## Light Up Points of Interest

Illuminate your key message with the red digital pointer or magnify the keypoint and impress your audience.



Digital Pointer

Highlight

Magnify

USB-A & USB-C 2-in-1 receiver



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



Made in China

## Specification:

Connectivity	RF 2.4 GHz wireless technology
Interface	USB-A/M, USB-C/M
Wireless Range	Up to 50 m in open area
Battery	3.7 V 250 mAh rechargeable Li-ion battery
LED Indicator	Green LED for activity
Compatibility	Computer/laptop with USB-A or USB-C port
Operating Temperature	0–45°C
Operating Humidity	25–50% RH (non-condensing)
Color	Silver
Dimensions	13 x 3 x 1.3 cm
Weight	51 g

## Package Contents:

- » 1x Wireless Presenter
- » 1x 2-in-1 USB Receiver
- » 1x USB Charging Cable
- » 1x Protective Case
- » 1x User Manual

## Package Information:

- » Packing Dimension: mm
- » Packing Weight: kg
- » Carton Dimension: mm
- » Carton Q'ty: pcs
- » Carton Weight: kg



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



ID0218



4 052792 077209

Made in China