

USB Type-C™ Docking Station for 1 x SATA HDD / SSD transparent

Description

This Docking Station by Delock enables an external connection of **one 2.5" or 3.5" SATA HDD or SSD** through the **USB-C™** interface. This solution does not require an external enclosure since the drive can just plug in directly into the docking station. The included USB cables allow the connection to a free USB Type-A or USB-C™ port.



Transparent enclosure

The **sturdy, transparent plastic housing** provides a view inside.

Item no. 64089

EAN: 4043619640898

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x SuperSpeed USB 10 Gbps (USB 3.2 Gen 2) USB Type-C™ female
 - 1 x SATA 6 Gb/s 22 pin receptacle
 - 1 x DC jack
- Chipset: VIA VL716
- On / Off switch
- For 2.5" and 3.5" SATA HDD / SSD
- Suitable for all SATA HDDs up to SATA 6 Gb/s
- Data transfer rate up to 6 Gb/s
- LED indicator for power and access
- Transparent plastic housing
- Dimensions (LxWxH): ca. 142 x 75 x 58 mm
- Plug & Play

Power supply specification

- Wall power supply
- Input: AC 100 ~ 240 V / 50 ~ 60 Hz / 1 A
- Output: 12 V / 2 A
- Ground outside, plus inside
- Dimensions:

inside: ø ca. 2.1 mm
outside: ø ca. 5.5 mm
length: ca. 10 mm


System requirements

- Chrome OS 74.0 or above
- Linux Kernel 3.3 or above
- Mac OS 10.14.5 or above
- Windows 7/7-64/8.1/8.1-64/10/10-64
- PC or laptop with a free USB Type-C™ port or
- PC or laptop with a free USB Type-A port

Package content

- Docking station
- Cable USB-C™ male to USB-C™ male, length ca. 50 cm
- Cable USB-C™ male to USB Type-A male, length ca. 1 m
- External power supply 12 V / 2 A
- User manual

Images

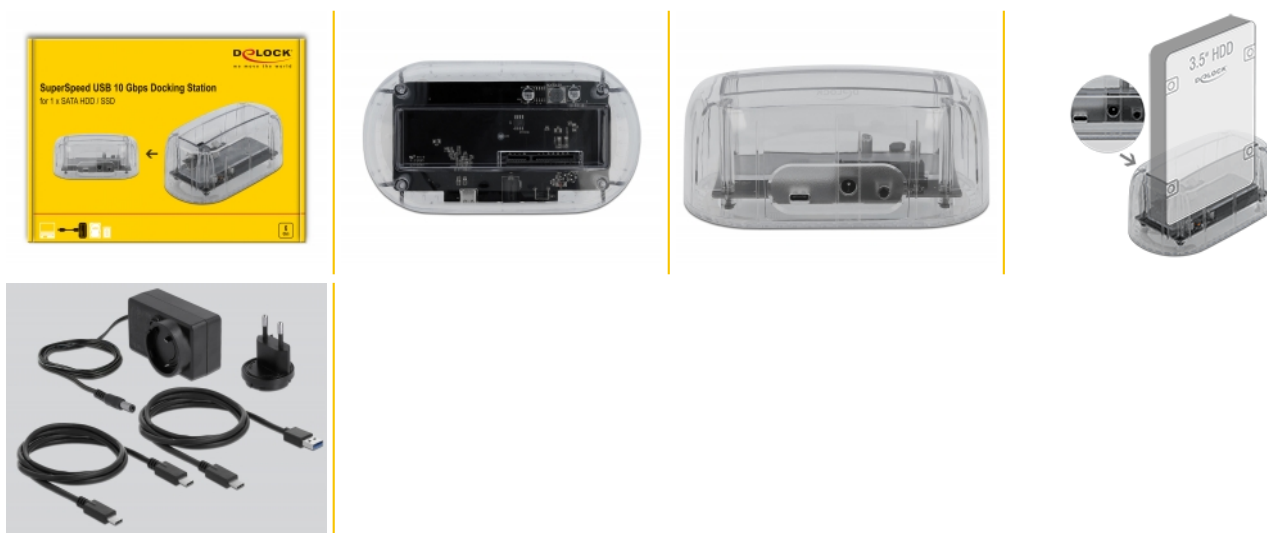

General

Function:	Plug & Play
Suitable for data medium:	2.5" 3.5" SSD or HDD
Supported operating system:	Chrome OS 74.0 or above Linux Kernel 3.3 or above Mac OS 10.14.5 or above Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit

Interface

External:	1 x DC jack 1 x USB 10 Gbps USB Type-C™ female
Internal:	1 x SATA 6 Gb/s 22 pin receptacle

Technical characteristics

Chipset:	VIA VL716
----------	-----------

Physical characteristics

Housing material:	Plastic
Length:	142 mm
Width:	75 mm
Height:	58 mm
Colour:	transparent

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin

Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de